





Product designation	Reversing contactor		
Product type designation	BGR12		
Electrical features			
Maximum operating current (≤440V)	A	12	
Contact characteristics			
Operational current Ie	AC-3 (≤440V ≤55°C)	A	12
Rated operational power AC-3 (T≤55°C)	230V	kW	3.2
	400V	kW	5.7
	415V	kW	6.2
	440V	kW	5.5
	500V	kW	5
	690V	kW	5
Built-in auxiliary contacts	NO	0	
	NC	1	
UL technical data			
Maximum UL/CSA horsepower ratings single-phase	110V-120V	HP	0.5
	220V-240V	HP	1.5
Maximum UL/CSA horsepower ratings three-phase, 3-pole	200V-208V	HP	3
	220V-240V	HP	3
	440V-480V	HP	7.5
	550V-600V	HP	10
Mechanical features			
Terminals type	Clamp screw		
Weight	g	460	
Dimensions			

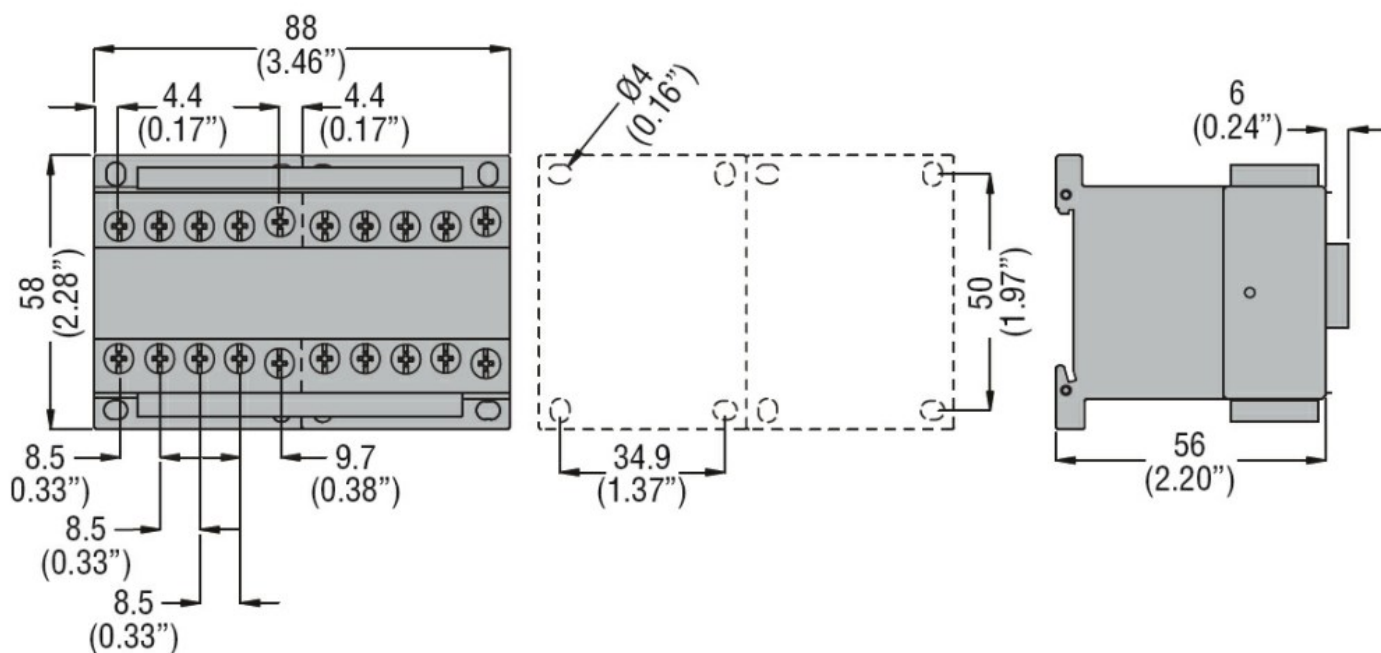

## Wiring diagrams

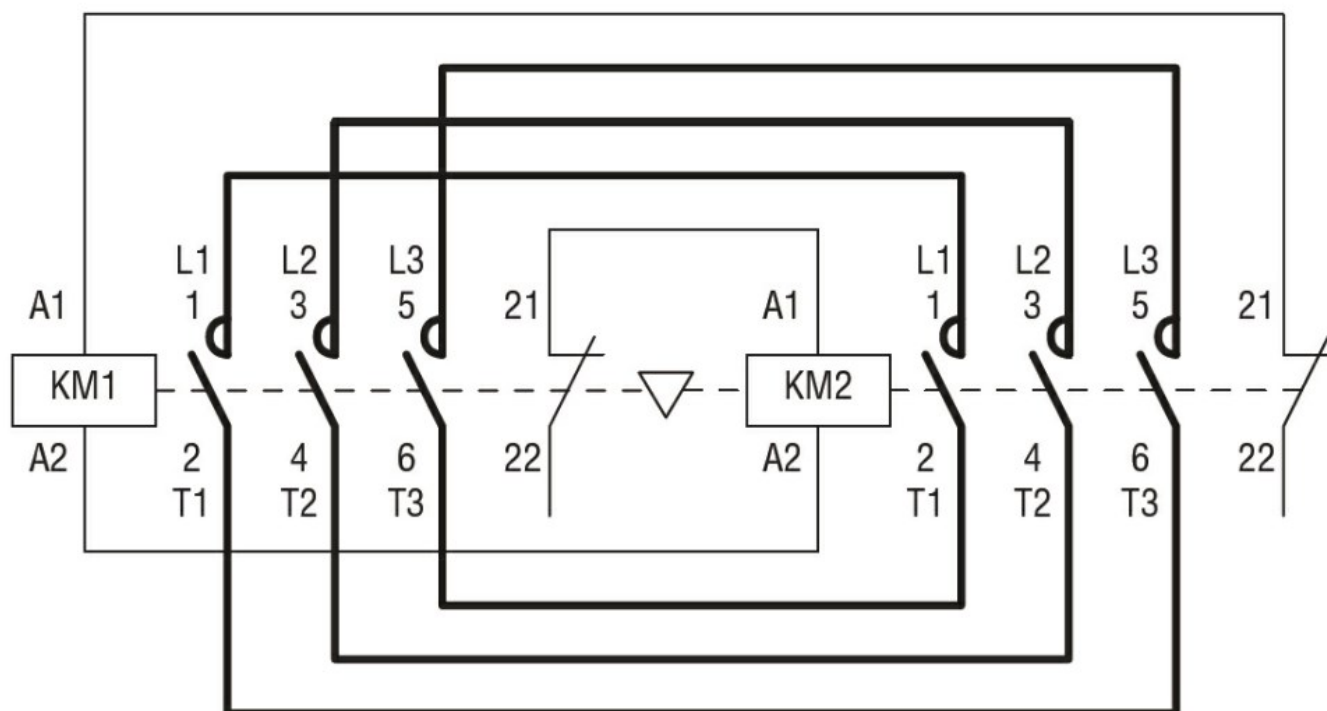

## Certifications and compliance

### Compliance

IEC/EN 60947-1  
IEC/EN 60947-4-1  
UL508 CSA C22.2 n° 14

### Certificates

cULus

## ETIM classification

ETIM 8.0

EC001037 -  
Motor  
starter/Motor  
starter  
combination