



Product designation	Probe
Product type designation	CGL125

Connections

Terminals type	Threaded rod with nut
----------------	-----------------------


Ambient conditions

Temperature	Operating temperature	max	°C	+180
Maximum operating pressure			bar	10

Housing

Weight	g	158
--------	---	-----

Dimensions

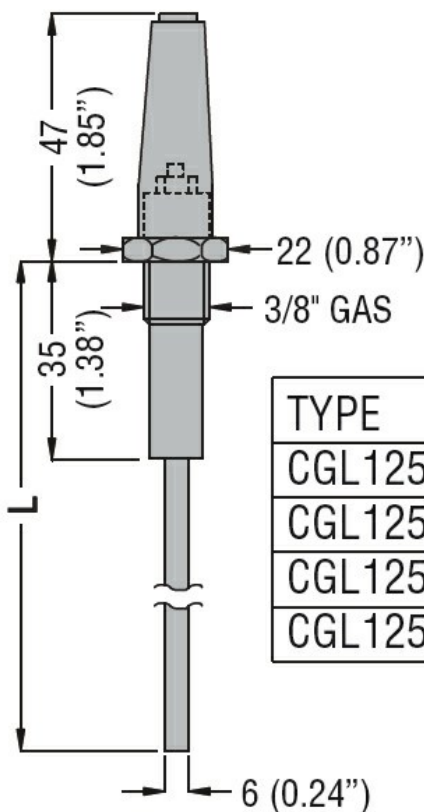

TYPE	L
CGL125 3	327 (12.87")
CGL125 5	500 (19.68")
CGL125 7	700 (27.56")
CGL125 10	1000 (39.37")

Certifications and compliance

Compliance	/
------------	---

Certificates	EAC
--------------	-----

ETIM classification

ETIM 8.0	EC010106 - Liquid level sensor
----------	--------------------------------