



Product designation

Signal beacons
Ø62mm/2.44"

Product type designation

8LB6EL

General characteristics

Diameter	mm - inch	62 / 2.44
Colour		Green
IEC degree of protection		IP54

Mechanical features

Tightening torque for terminals max	Nm	0.5
Terminals screw		Screw clamp terminals
Conductor section		

AWG/Kcmil

max 16

IEC

max mm² 1.5
g 60

Weight


Ambient conditions

Temperature


Operating temperature

min °C -20
max °C +50

Dimensions

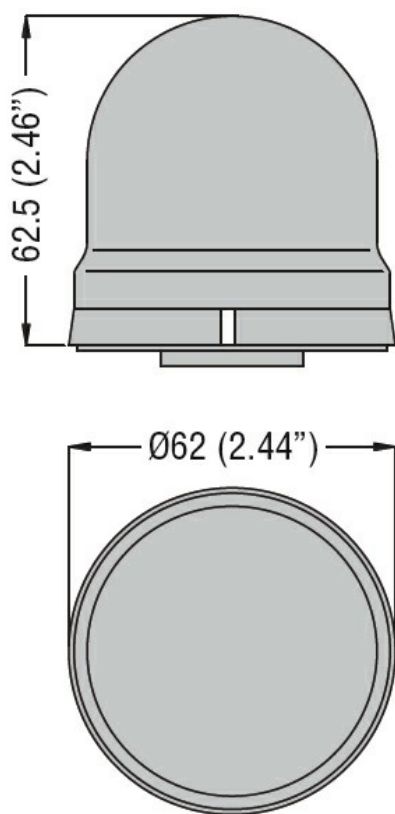

Wiring diagrams

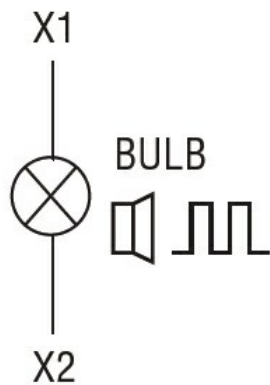

Certifications and compliance

Compliance	IEC/EN 60947-1
	IEC/EN 60947-5-1
Certificates	EAC

ETIM classification	
ETIM 8.0	EC000232 - Optical module for signal tower