





Product designation				Signal tower	
Product type designation				Ø45mm/1.7"	
8TL4					
General characteristics					
Diameter			mm - inch		45 / 1.77
Supply voltage (DC)			V		24±10%
Colour			Green, red		
IEC degree of protection			IP54		
Light consumption per module (DC)			mA		37
Mechanical features					
Tightening torque for terminals max			Nm		0.5
Terminals screw			Screw clamp terminals		
Conductor section					
AWG/Kcmil		max		16	
				IEC	
		max		mm²	1.5
Weight			g		160
Ambient conditions					
Temperature					
Operating temperature		min		°C	-20
		max		°C	+50
Dimensions					

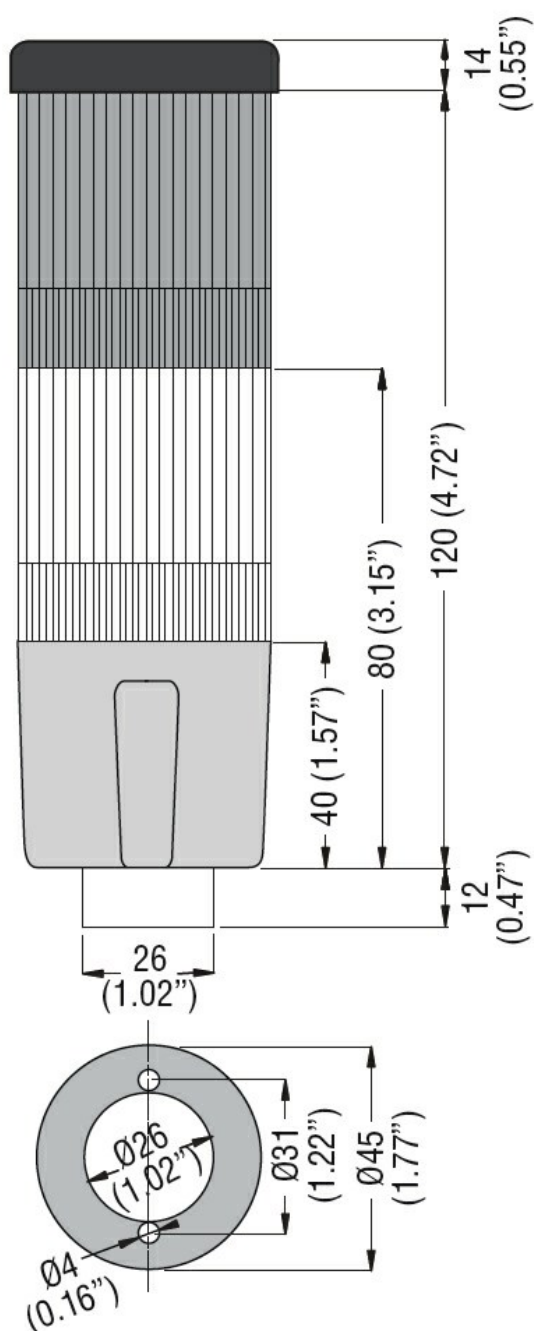

Wiring diagrams

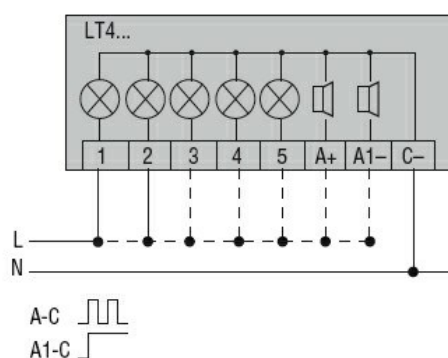

Certifications and compliance

Compliance

CSA C22.2 n° 14

IEC/EN 60947-1

IEC/EN 60947-5-1

UL508

Certificates

cULus

EAC

ETIM classification

ETIM 8.0

EC001042 -
Signal tower
complete