



Product designation

Product type designation

Signal tower
Ø70mm/2.75"
8TL7FL - Light
modules

General characteristics

| | | |
|-----------------------------------|-----------|-----------|
| Diameter | mm - inch | 70 / 2.75 |
| Supply voltage (AC) | V | 24 |
| Supply voltage (DC) | V | 24 |
| Colour | | Red |
| IEC degree of protection | | IP65 |
| Light consumption per module (AC) | mA | 135 |
| Light consumption per module (DC) | mA | 75 |
| Sound module consumption (AC) | mA | 135 |
| Sound module consumption (DC) | mA | 75 |

Mechanical features

| | | |
|--------|---|----|
| Weight | g | 92 |
|--------|---|----|


Ambient conditions

Temperature


Operating temperature

| | | |
|-----|----|-----|
| min | °C | -20 |
| max | °C | +50 |

Dimensions

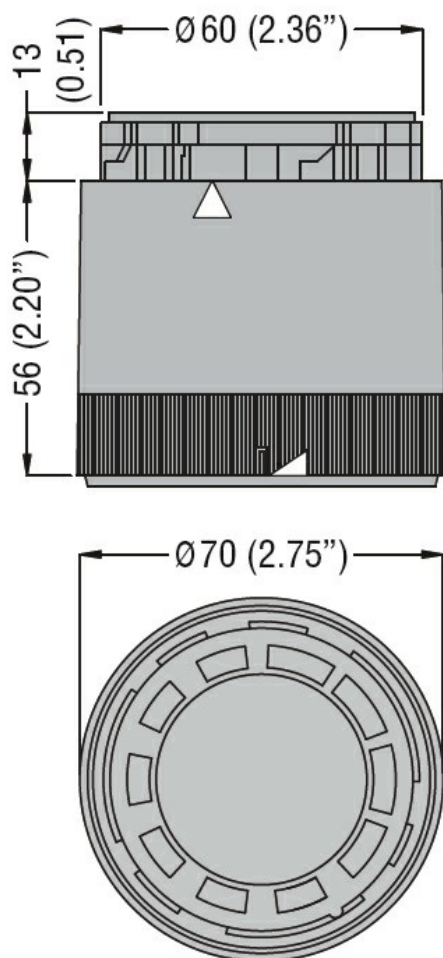

Wiring diagrams

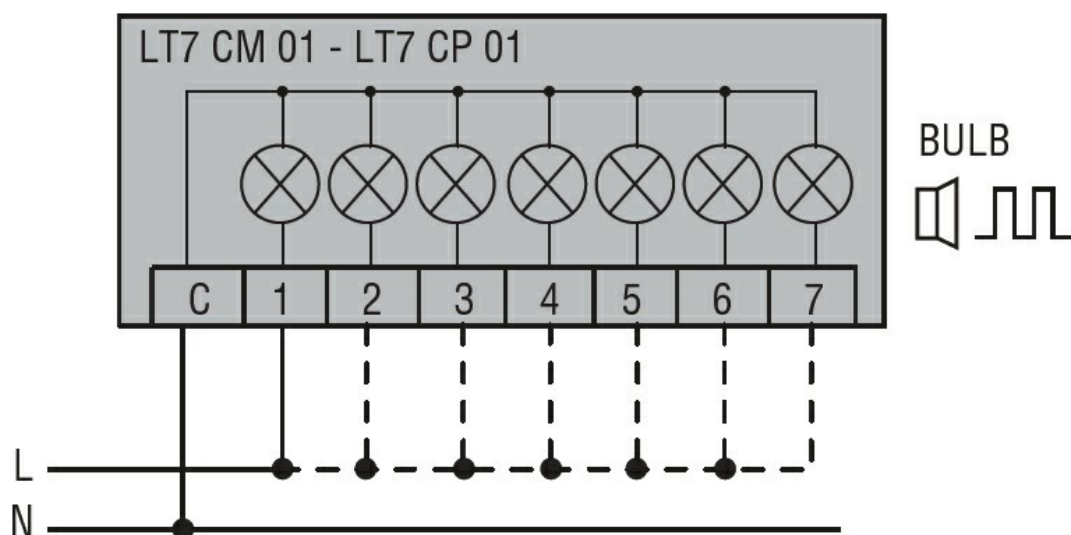

Connect terminals C and 1 as indicated to power the first module.
If other modules are fitted, the respective terminals must be connected accordingly.

Certifications and compliance

Compliance

CSA C22.2 n° 14

IEC/EN 60947-1

IEC/EN 60947-5-1

UL508

Certificates

cULus

EAC

ETIM classification

ETIM 8.0

EC000232 -
Optical module
for signal tower