



Enclosed
automatic
transfer switches
ATS
ATP

Product designation

Product type designation

Voltage inputs

Maximum rated voltage Ue		400
Frequency range	Hz	45...65

Current inputs

Rated current (Ie)	A	45 (AC1)
--------------------	---	----------

Digital inputs

Number of digital input	Nr.	6
-------------------------	-----	---

Relay outputs

Number of relay output	Nr.	7
------------------------	-----	---

Contact arrangement

6 with 1NO -
SPST 1 with
NO/NC - SPDT

Insulations

Voltage inputs			
	Rated insulation voltage Ui	VAC	400
	Rated impulse withstand voltage Uimp	kV	4


Ambient conditions

Maximum Pollution degree	2
Overvoltage category	3


Housing

Material	Metallic	
Degree of protection	IP65	
Dimensions (W x H x D)	mm	500x400x200

Dimensions

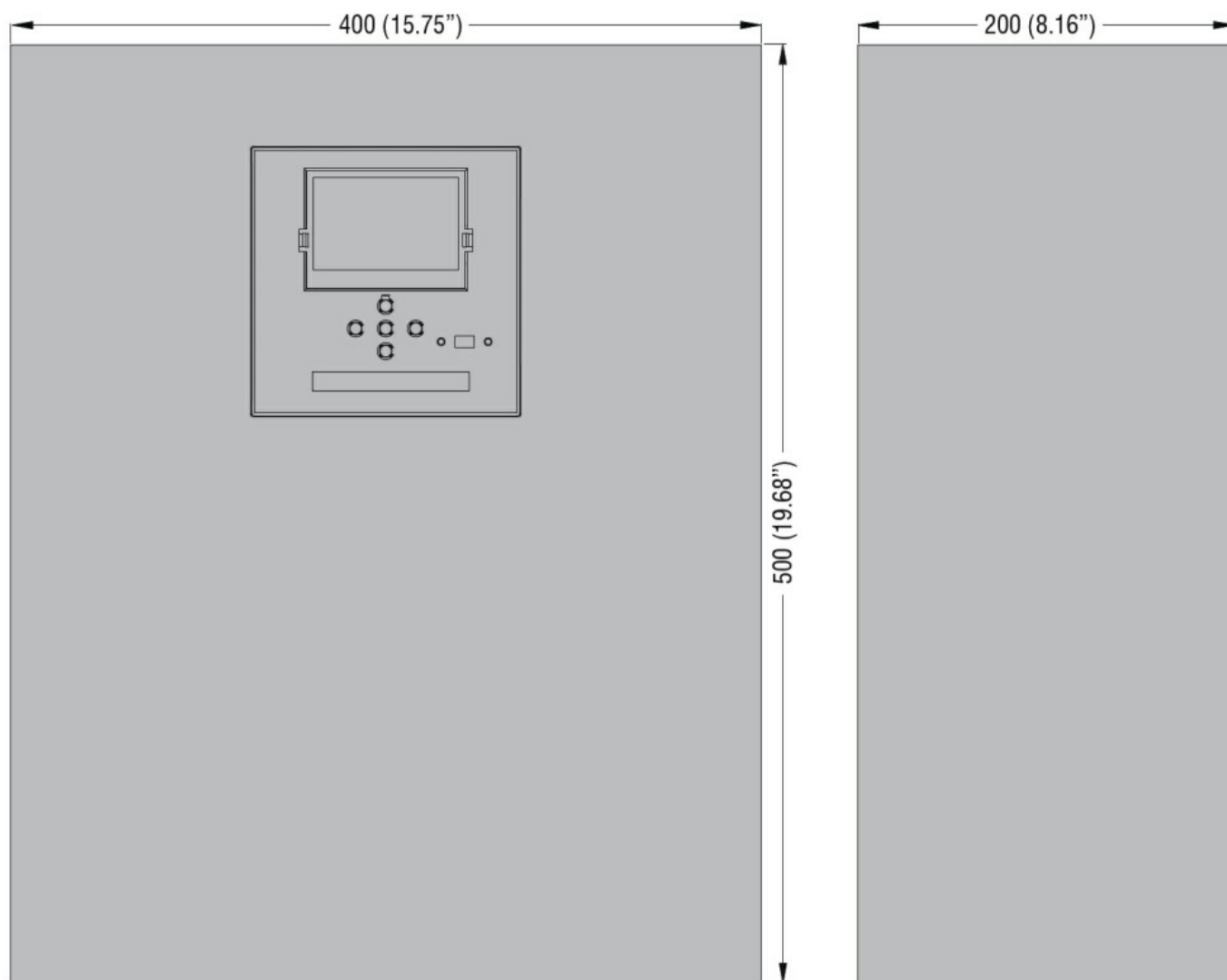

Wiring diagrams

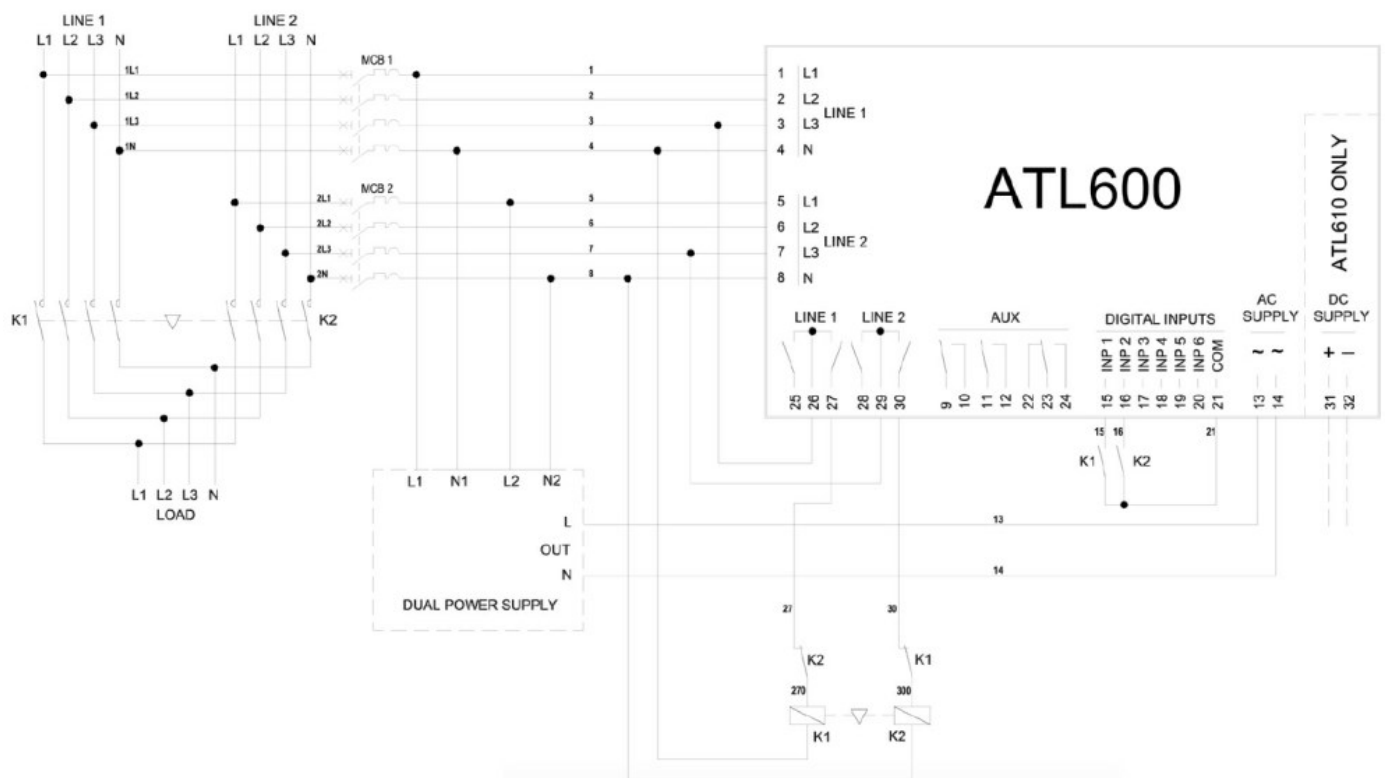

Certifications and compliance

Compliance

IEC 61439-2