



Product designation

Product type designation

Type of CT

Current  
transformers  
DM1TA0300  
Split-core

### Current inputs

Primary current $I_{pn}$ (/5)	A	300
Operational frequency	min max	Hz Hz 50 60
Secondary output current	A	5
Overload withstand $I_{pn}$	%	120
Burden	cl. 0.5 cl. 1	VA VA 1.5 3

### Insulations

Rated insulation voltage $U_i$ IEC/EN	V	720
IEC rated short-time thermal current $I_{th}$	$I_{th}$ for s	40...60
IEC rated dynamic current $I_{dyn}$	$I_{th}$ for s	2.5
Insulation dry type		Class E

### Mechanical features

Terminals type		Screw
Fixing		Screw fixing
Weight	g	900

### Ambient conditions

Temperature

Operating temperature


min	°C	-25
max	°C	+50

Storage temperature

min	°C	-40
max	°C	+80

Relative humidity	%	90
Protection degree		IP30

### Dimensions

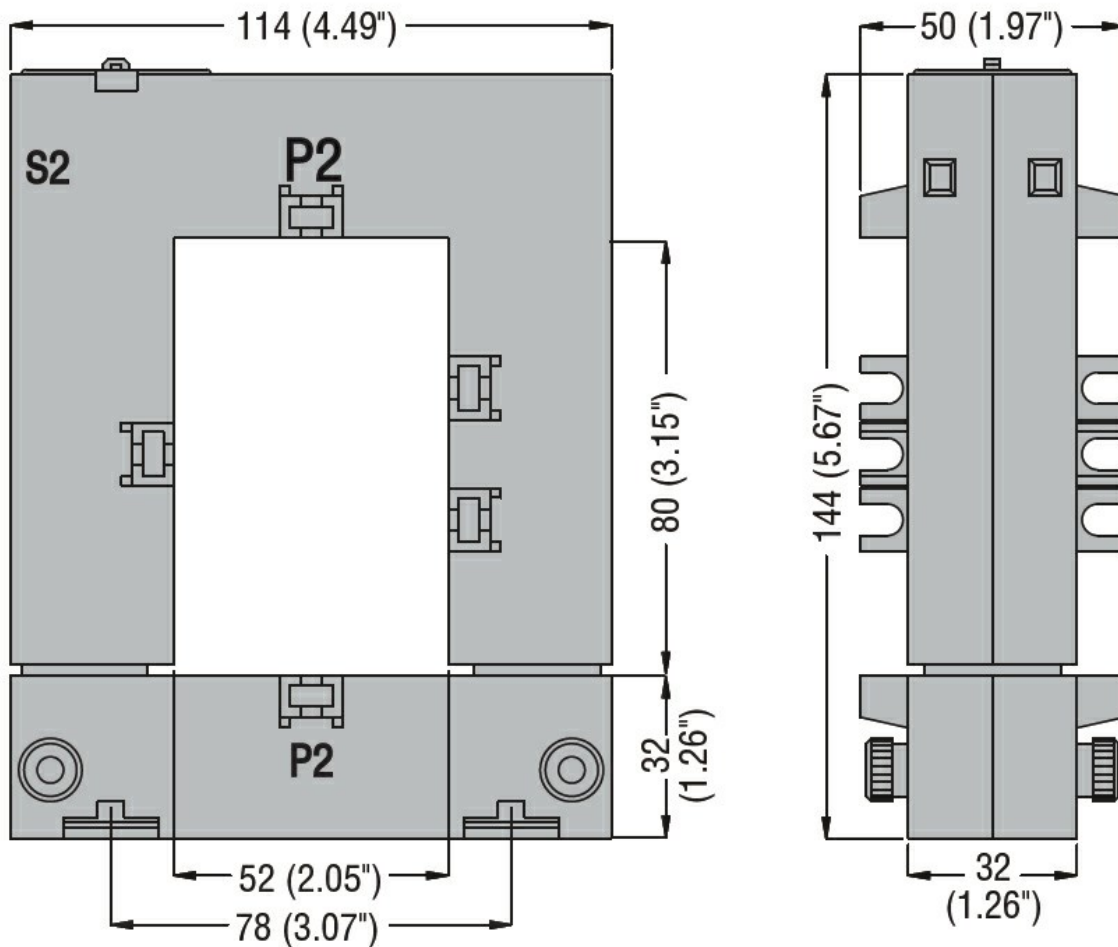

### Certifications and compliance

#### Certifications

IEC/EN 60044-1

#### Compliance

EAC

### ETIM classification

EC000066 - Power contactor, AC switching

□