




Product designation			Current transformers		
Product type designation			DM1TMA0200		
Type of CT			Split-core		
Current inputs					
Primary current I <sub>pn</sub> (/5)			A	200	
Operational frequency			min	Hz	50
			max	Hz	60
Secondary output current			A	5	
Overload withstand I <sub>pn</sub>			%	120	
Burden			cl. 1	VA	1
Insulations					
Rated insulation voltage U <sub>i</sub> IEC/EN			V	720	
IEC rated short-time thermal current I <sub>th</sub>			I <sub>th</sub> for s	40...60	
IEC rated dynamic current I <sub>dyn</sub>			I <sub>th</sub> for s	2.5	
Insulation dry type			Class E		
Mechanical features					
Terminals type			2m pre-wired		
Weight			g	200	
Ambient conditions					
Temperature					
Operating temperature			min	°C	-25
			max	°C	+50
Storage temperature			min	°C	-40
			max	°C	+80
Relative humidity			%	90	
Dimensions					

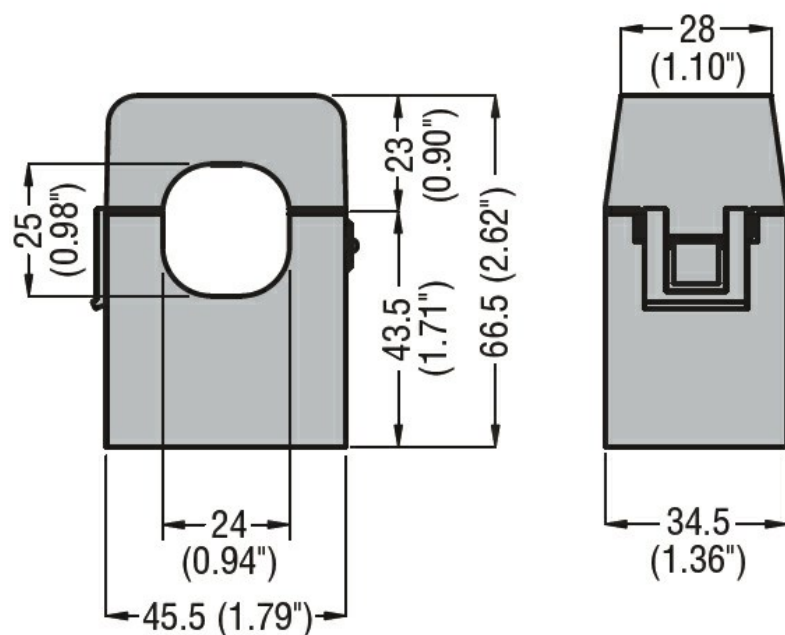

#### Certifications and compliance

##### Certifications

IEC/EN/BS 61869-1

IEC/EN/BS 61869-2

##### Compliance

EAC

#### ETIM classification

EC000066 - Power contactor, AC switching