




Product designation				SOCKET	
Product type designation				HR1XS024S	
Contact characteristics					
Rated insulation voltage Ui IEC/EN				V	250
Rated impulse withstand voltage Uimp				kV	4
Coil characteristics					
Relay control voltage + socket				V	12...24VAC/DC
Mechanical features					
Socket screw tightening tool (cross / flat blade)				Phillips 0/3.5mm	
Conductor section					
AWG/Kcmil		min		20	
		max		16	
IEC		min		mm²	0.5
		max		mm²	1.5
Fixing				On 35mm DIN rail	
Dimensions					

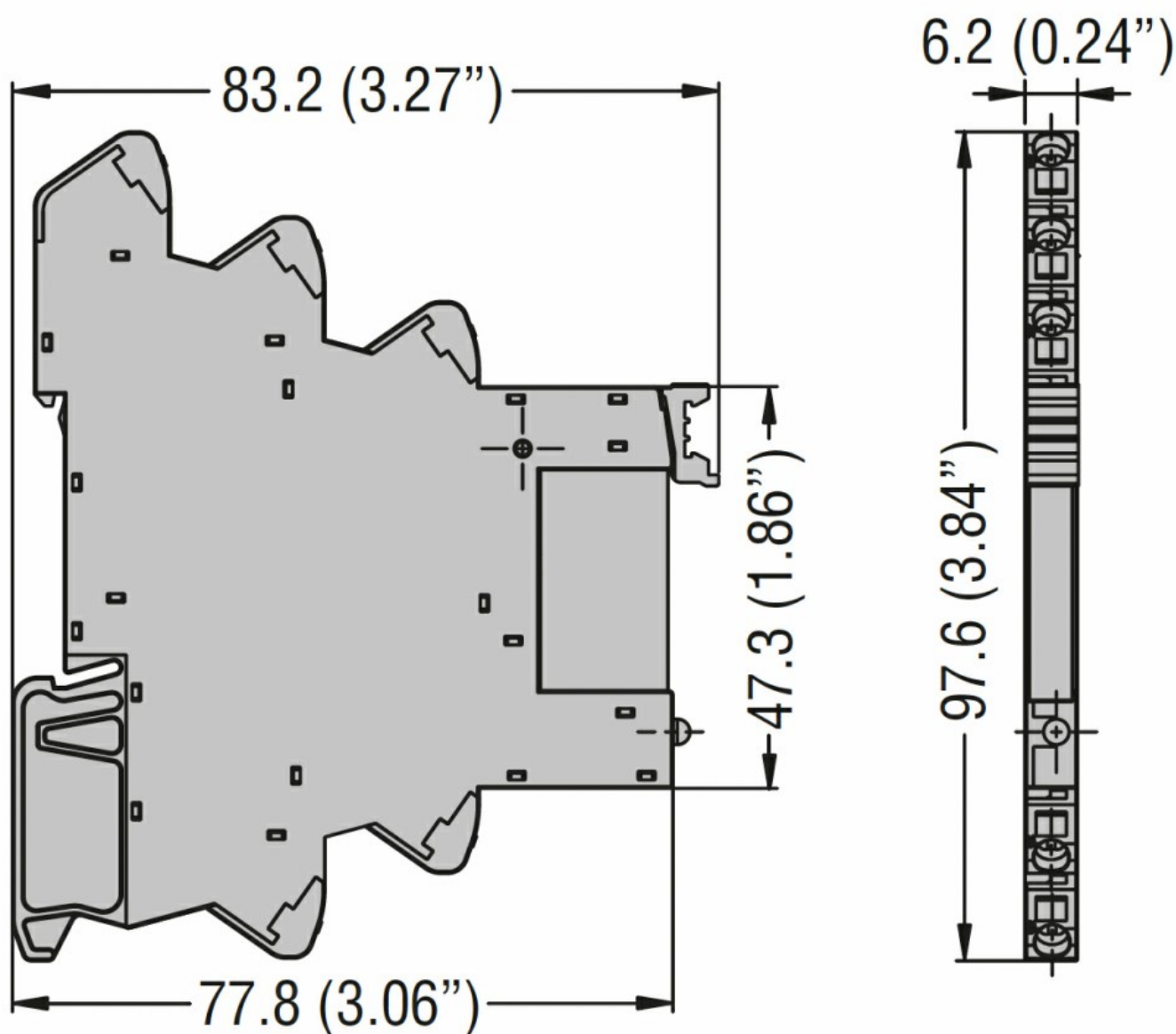


Wiring diagrams



12 NC

11 COM

14 NO

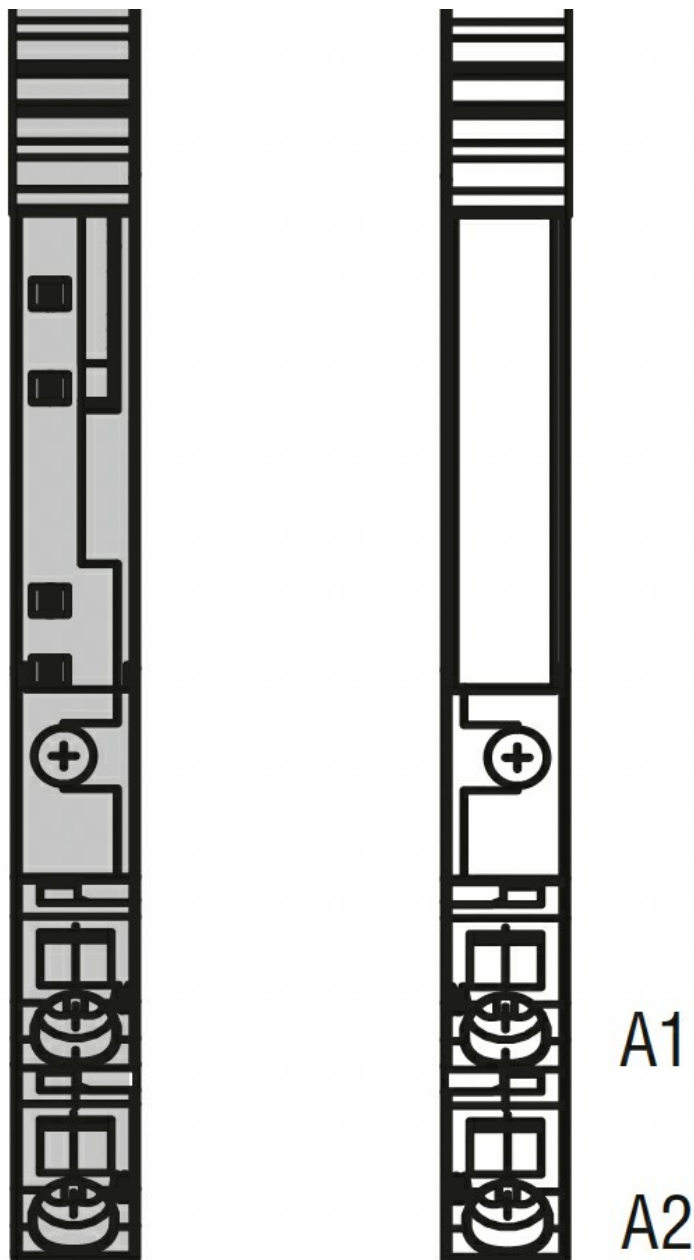

Certifications and compliance

Compliance

IEC/EN 61810

Certificates

CSA

cURus

EAC

ETIM classification

ETIM 8.0

EC001456 -
Relay socket