



Product designation

SOCKET

Product type designation

HR5XS22

Contact characteristics

Rated insulation voltage U_i IEC/EN	V	250
Rated impulse withstand voltage U_{imp}	kV	4

Mechanical features

Socket screw tightening tool (cross / flat blade)	Phillips 1/4.5mm
---	------------------

Conductor section

AWG/Kcmil

min	20
max	14


IEC

min	mm ²	0.5
max	mm ²	2.5

Fixing


On 35mm DIN
rail and with
screw

Dimensions

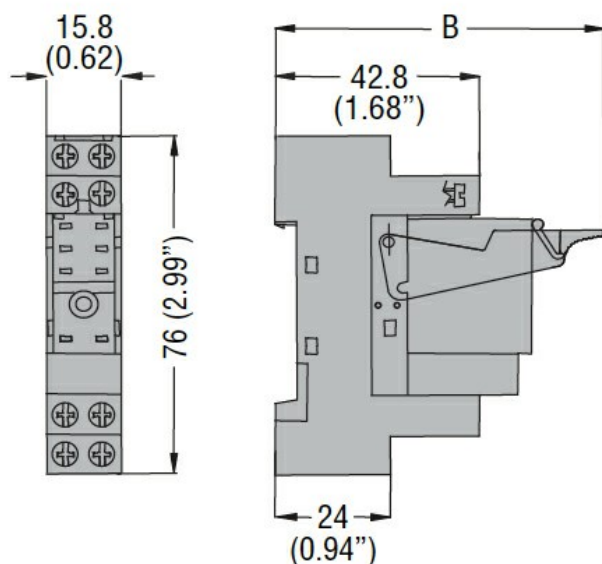

B: 72.5mm (2.85") con HR3X88
82.5mm (3.25) con XR5X88

Wiring diagrams

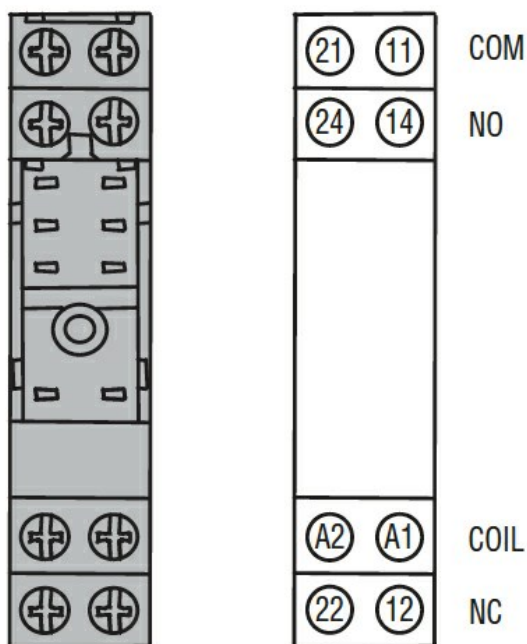

Certifications and compliance

Compliance

IEC/EN 61810

Certificates

CSA

cULus

cURus

EAC

ETIM classification

ETIM 8.0

EC001456 -
Relay socket