



Mushroom head  
pushbutton,  
spring return Ø  
40mm/1.6"  
LPCB614

Product designation

Product type designation

#### General characteristics

Colour	Yellow
Type of positions	Mushroom head pushbutton
Material	Polyamide
IEC degree of protection	IP66, IP67 and IP69K

#### Mechanical features

Operating force	kg-lb	<0.5Kg / 1.1lb
Mechanical life - spring return actuators	cycles	5000000
Mounting adapter		LPXAU120
Weight	g	33

#### UL technical data

UL degree of protection	Type1, 2, 3R, 4, 4X, 12, 12K
-------------------------	---------------------------------

#### Ambient conditions

Temperature


Operating temperature

min	°C	-25
max	°C	+70

Storage temperature

min	°C	-40
max	°C	+85

#### Dimensions

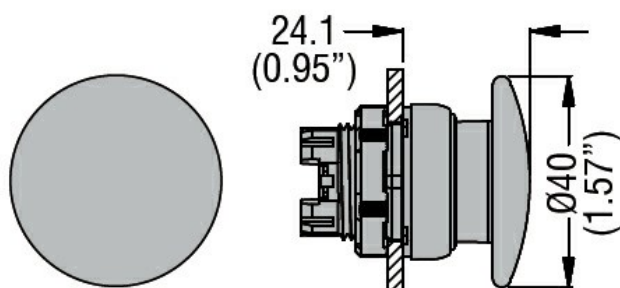

#### Certifications and compliance

Compliance

CSA C22.2 n° 14  
IEC/EN/BS 60947-1  
IEC/EN/BS 60947-5-1  
UL508

Certificates

CCC	
cULus	
EAC	
RINA	

ETIM classification

ETIM 8.0

EC001038 -  
Front element for  
mushroom push-  
button