



Double-touch  
actuators, spring  
return - One  
extended and  
one flush  
pushbuttons  
LPCB72

Product designation

Product type designation

#### General characteristics

|                          |  |
|--------------------------|--|
| Colour                   | Black/Red  |
| Type of positions        | Double-touch<br>with one<br>extended and<br>one flush<br>pushbuttons |
| Material                 | Polyamide  |
| IEC degree of protection | IP66, IP67 and<br>IP69K  |

#### Mechanical features

|                  |        |                |
|------------------|--------|----------------|
| Operating force  | kg-lb  | <0.5Kg / 1.1lb |
| Mechanical life  | cycles | 1000000        |
| Mounting adapter |        | LPXAU120       |
| Weight           | g      | 30             |

#### UL technical data

|                         |                                 |
|-------------------------|---------------------------------|
| UL degree of protection | Type1, 2, 3R, 4,<br>4X, 12, 12K |
|-------------------------|---------------------------------|

#### Ambient conditions

Temperature


Operating temperature

|     |    |     |
|-----|----|-----|
| min | °C | -25 |
| max | °C | +70 |

Storage temperature

|     |    |     |
|-----|----|-----|
| min | °C | -40 |
| max | °C | +85 |

#### Dimensions

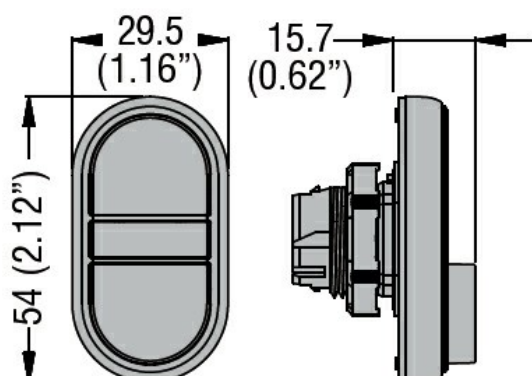

#### Certifications and compliance

Compliance

CSA C22.2 n° 14

IEC/EN/BS 60947-1

IEC/EN/BS 60947-5-1

UL508

Certificates

CCC

cULus

EAC

RINA

ETIM classification

ETIM 8.0

EC000221 -  
Front element for  
push button