



USB interface,
A/A female type
connection with
0.5m long cable
LPFD0

Product designation

Product type designation

General characteristics

Material

Aluminium and
zinc alloy for the
metal part,
polyamide for
plastic parts

IEC degree of protection

IP66, IP67 and
IP69K

UL technical data

UL degree of protection

1, 2, 3R, 4, 4X,
12, 12K on front

Ambient conditions

Temperature


Operating temperature

min	°C	-25
max	°C	+70

Storage temperature

min	°C	-40
max	°C	+85

Dimensions

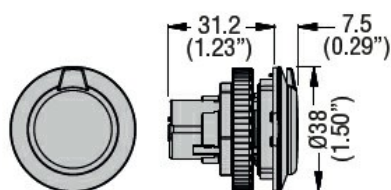

Certifications and compliance

Compliance

CSA C22.2 n° 14
IEC/EN/BS 60947-1
IEC/EN/BS 60947-5-1
UL508

Certificates

cULus

ETIM classification

ETIM 8.0

EC002780 -
Interface module