



Illuminated  
mushroom head  
button actuators -  
Latch, turn to  
release Ø  
40mm/1.6"  
LPSBL66

Product designation

Product type designation

#### General characteristics

Colour	Red
Type of positions	Mushroom head pushbutton
Material	Aluminium and zinc alloy for metal parts and polyamide for plastic parts
IEC degree of protection	IP66, IP67 and IP69K

#### Mechanical features

Mechanical life - spring return actuators	cycles	5000000
Fixing		Without mounting adapter
Mounting adapter		LPXAU120M


#### UL technical data

UL degree of protection	Type1, 2, 3R, 4, 4X, 12, 12K
-------------------------	------------------------------

#### Ambient conditions

Temperature			
Operating temperature			
	min	°C	-25
	max	°C	+70
Storage temperature			
	min	°C	-40
	max	°C	+85

#### Dimensions

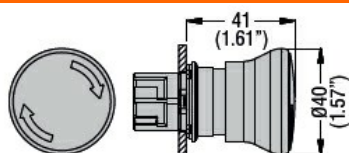

#### Certifications and compliance

Compliance	
	CSA C22.2 n° 14
	IEC/EN/BS 60947-1
	IEC/EN/BS 60947-5-1
	UL508

#### Certificates

cULus

ETIM classification

ETIM 8.0

EC001038 -  
Front element for  
mushroom push-  
button