



Enclosures with  
cut-outs for  
Ø22mm units -  
with multiholes  
for 12 actuators  
LPZM

Product designation

Product type designation

General characteristics

Colour Grey

IEC degree of protection IP66 and IP67

Mechanical features

Weight g 1360


UL technical data

UL degree of protection NEMA 4X

Ambient conditions

Temperature				
Operating temperature		min	°C	-25
		max	°C	+70
Storage temperature		min	°C	-40
		max	°C	+85

Dimensions

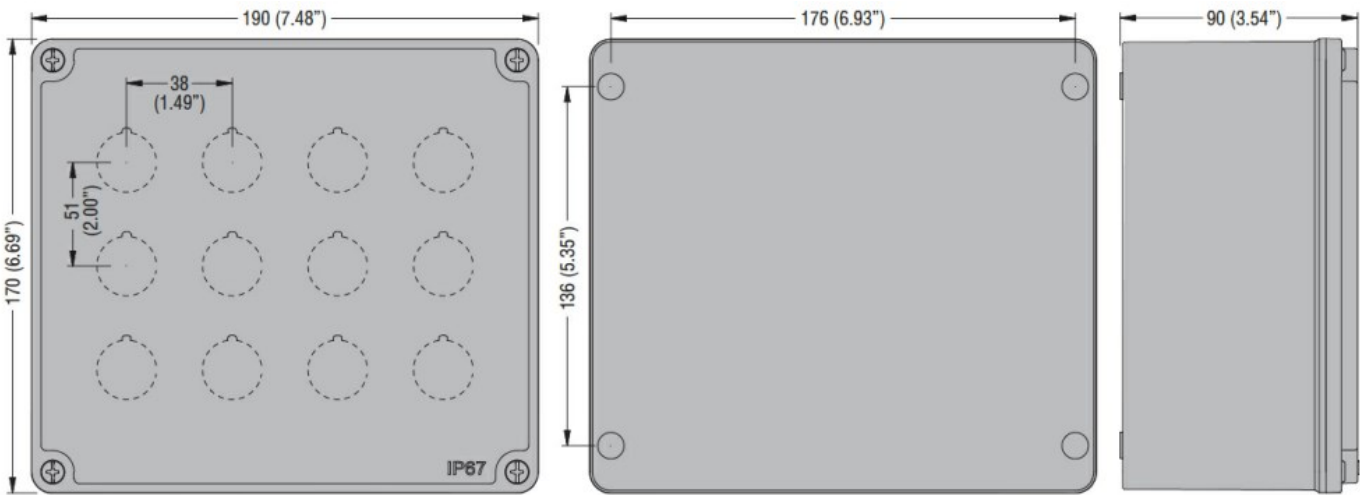

Certifications and compliance

Compliance IEC/EN 60947-5-1

Certificates cULus

EAC

ETIM classification

ETIM 8.0

EC000200 -  
Enclosure for  
control circuit  
devices