

Product designation
Product type designation

Enclosures
LPZM

General characteristics

Colour	Yellow
IEC degree of protection	IP66 and IP67

Mechanical features

Weight	g	346
--------	---	-----

UL technical data

UL degree of protection	NEMA 4X
-------------------------	---------

Ambient conditions

Temperature


Operating temperature

min	°C	-25
max	°C	+70

Storage temperature

min	°C	-40
max	°C	+85

Dimensions

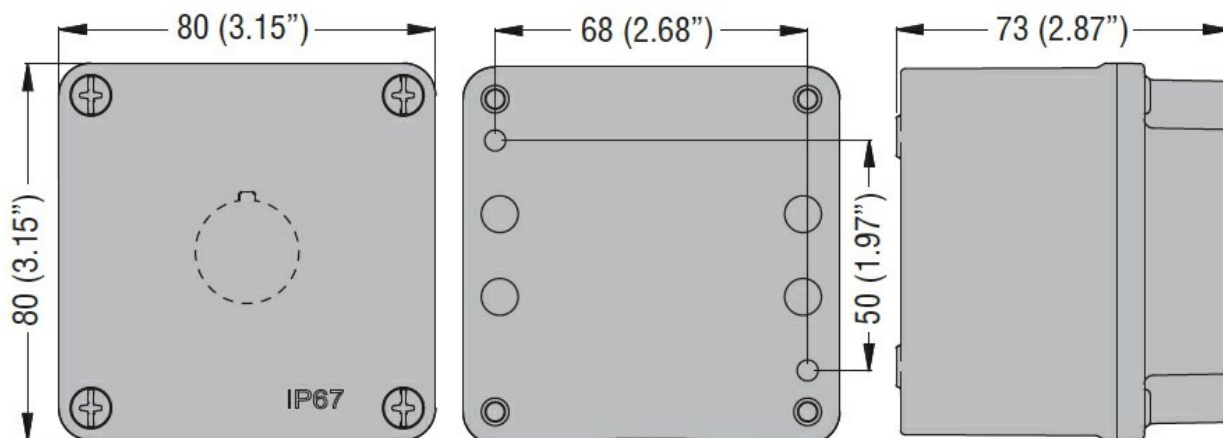

Certifications and compliance

Compliance

IEC/EN 60947-5-1

Certificates

cULus

EAC

ETIM classification

ETIM 8.0

EC000200 -
Enclosure for
control circuit
devices