



Enclosures with  
cut-outs for  
Ø22mm units -  
with hole for 3  
actuators  
LPZM

Product designation

Product type designation

#### General characteristics

Colour	Grey
IEC degree of protection	IP66 and IP67

#### Mechanical features

Weight	g	603
--------	---	-----

#### UL technical data

UL degree of protection	NEMA 4X
-------------------------	---------

#### Ambient conditions

Temperature


Operating temperature

min	°C	-25
max	°C	+70

Storage temperature

min	°C	-40
max	°C	+85

#### Dimensions

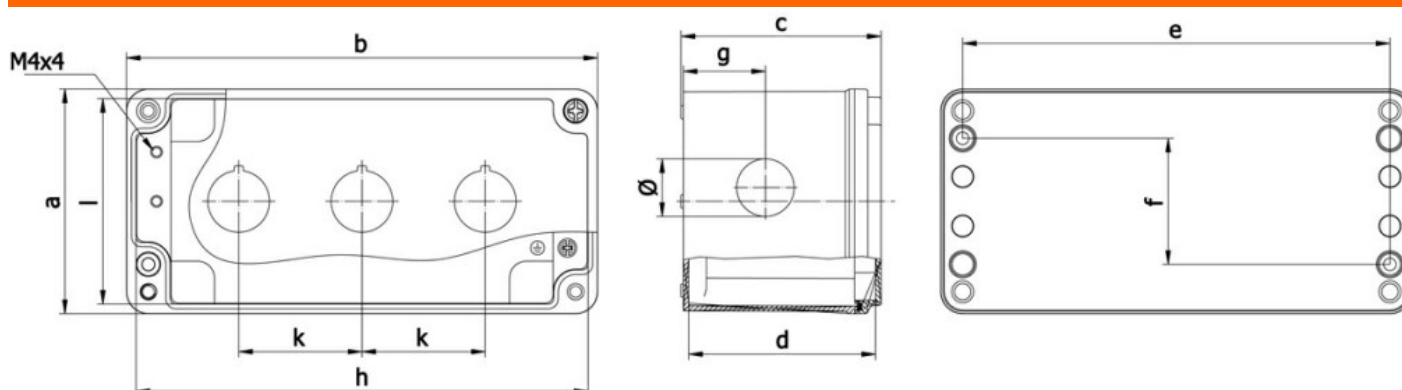

a	b	c	d	e	f	g	h	l	k	Ø
80	170	73	67	156	46	30	165	75	45	21

#### Certifications and compliance

Compliance

CSA C22.2 n° 14  
IEC/EN 60947-1  
IEC/EN 60947-5-1  
UL508

Certificates

cULus  
EAC

ETIM classification

ETIM 8.0

EC000200 -  
Enclosure for  
control circuit  
devices