




Product designation			Enclosures	
Product type designation			LPZM	
General characteristics				
Colour			Grey	
IEC degree of protection			IP66 and IP67	
Mechanical features				
Weight		g	680	
UL technical data				
UL degree of protection			NEMA 4X	
Ambient conditions				
Temperature				
Operating temperature		min	°C	-25
		max	°C	+70
Storage temperature		min	°C	-40
		max	°C	+85
Dimensions				

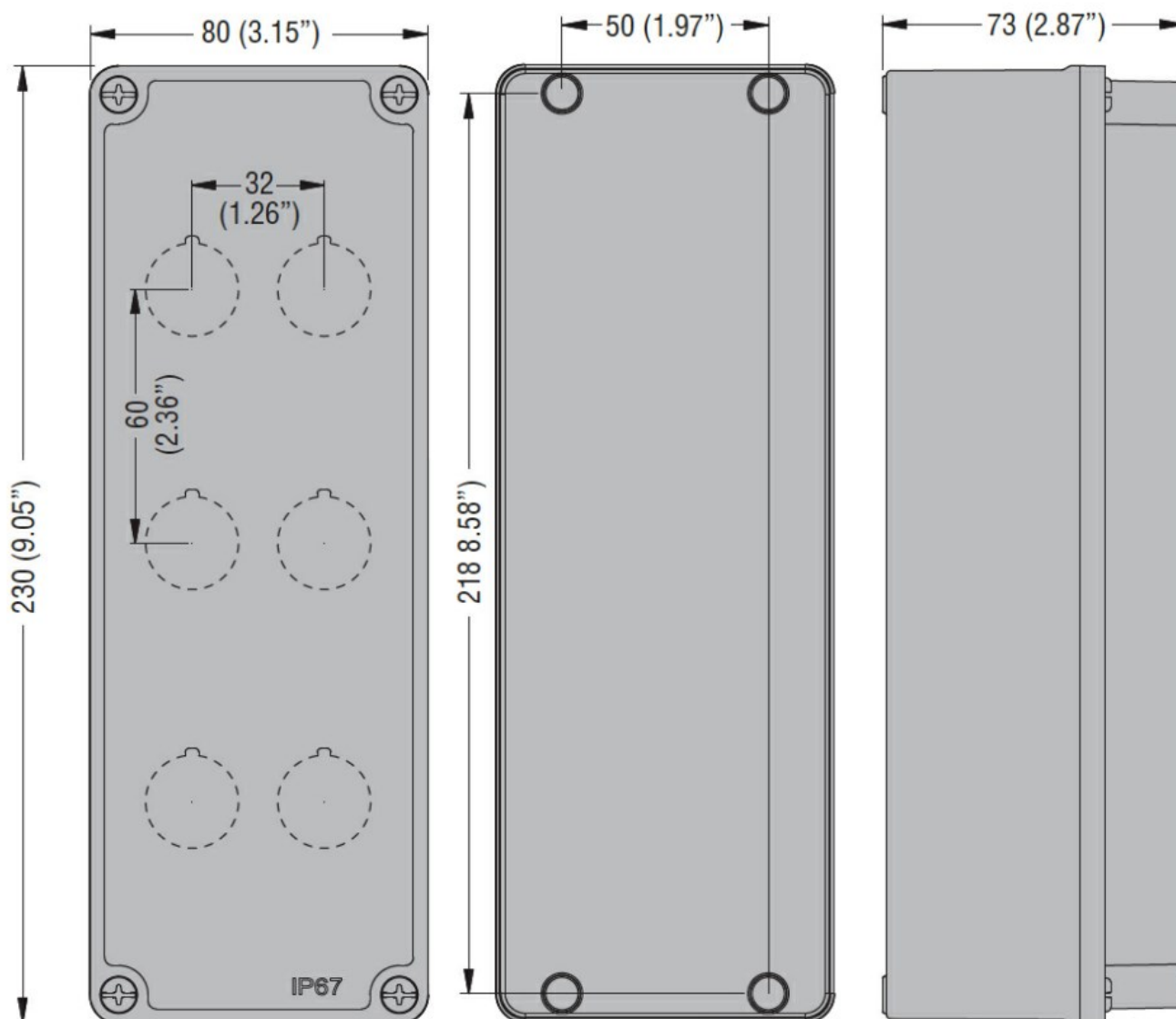

Certifications and compliance

Compliance

IEC/EN 60947-5-1

Certificates

cULus

EAC

ETIM classification

ETIM 8.0

EC000200 -
Enclosure for
control circuit
devices