



Plastic control
station with one
actuators -
Yellow, 1 way
LPZP1A5
LPZP1B502

Product designation

Product type designation

General characteristics

Colour	Yellow
Type of positions	Mushroom head pushbutton
Material	Polycarbonate
IEC degree of protection	IP66, IP67, IP69K

Mechanical features

Tightening torque for terminals max	Nm	1.8
Weight	g	135

Ambient conditions

Temperature


Operating temperature

min	°C	-25
max	°C	+70


Storage temperature

min	°C	-40
max	°C	+85

Dimensions

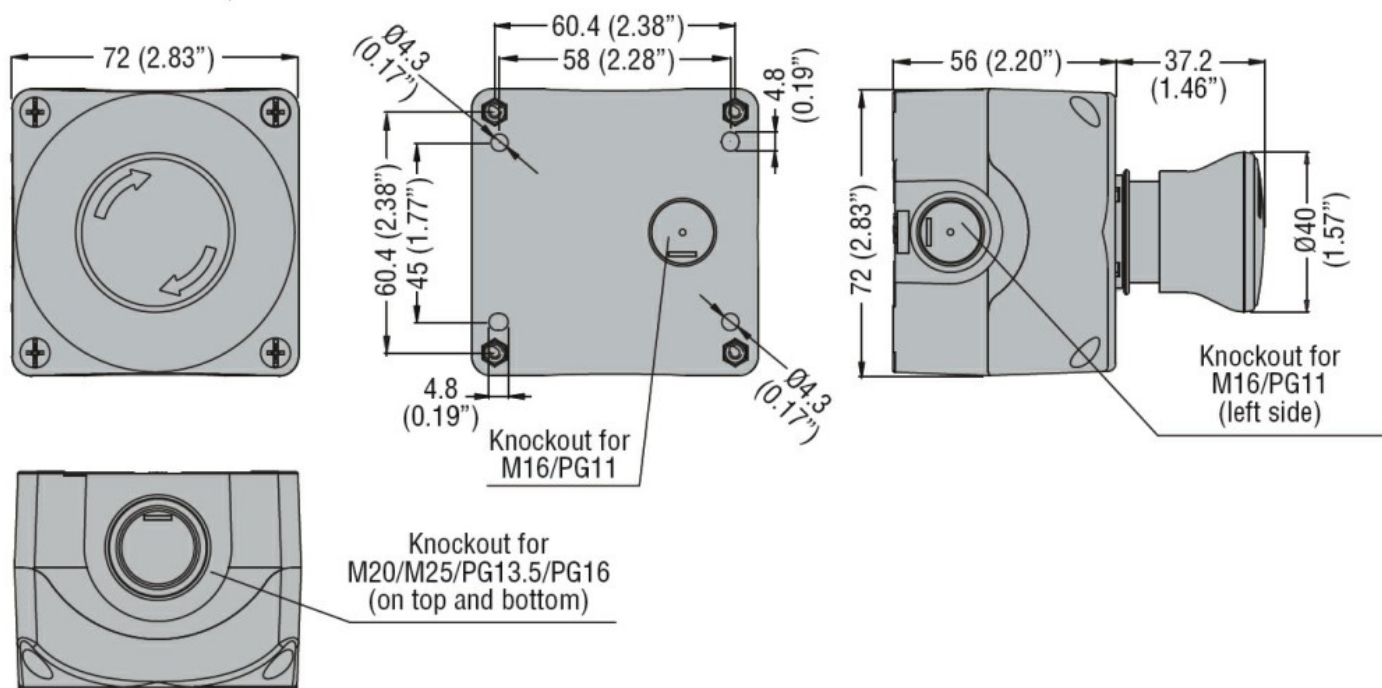

Wiring diagrams

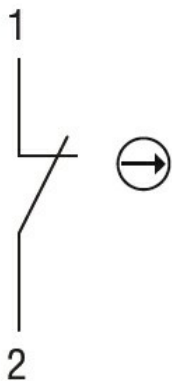

Certifications and compliance

Compliance	CSA C22.2 n° 14
	IEC/EN 60947-1
	IEC/EN 60947-5-1
	UL508

Certificates	cULus
	EAC

ETIM classification

ETIM 8.0	EC000200 - Enclosure for control circuit devices
----------	---