



Plastic control station with one actuators - Grey, 1 way LPZP1A8 LPZP1B801

Product designation

Product type designation

General characteristics

Colour	Grey
Type of positions	Mushroom head pushbutton
Material	Polycarbonate
IEC degree of protection	IP66, IP67, IP69K

Mechanical features

Tightening torque for terminals max	Nm	1.8
Weight	g	150

Ambient conditions

Temperature


Operating temperature

min	°C	-25
max	°C	+70


Storage temperature

min	°C	-40
max	°C	+85

Dimensions

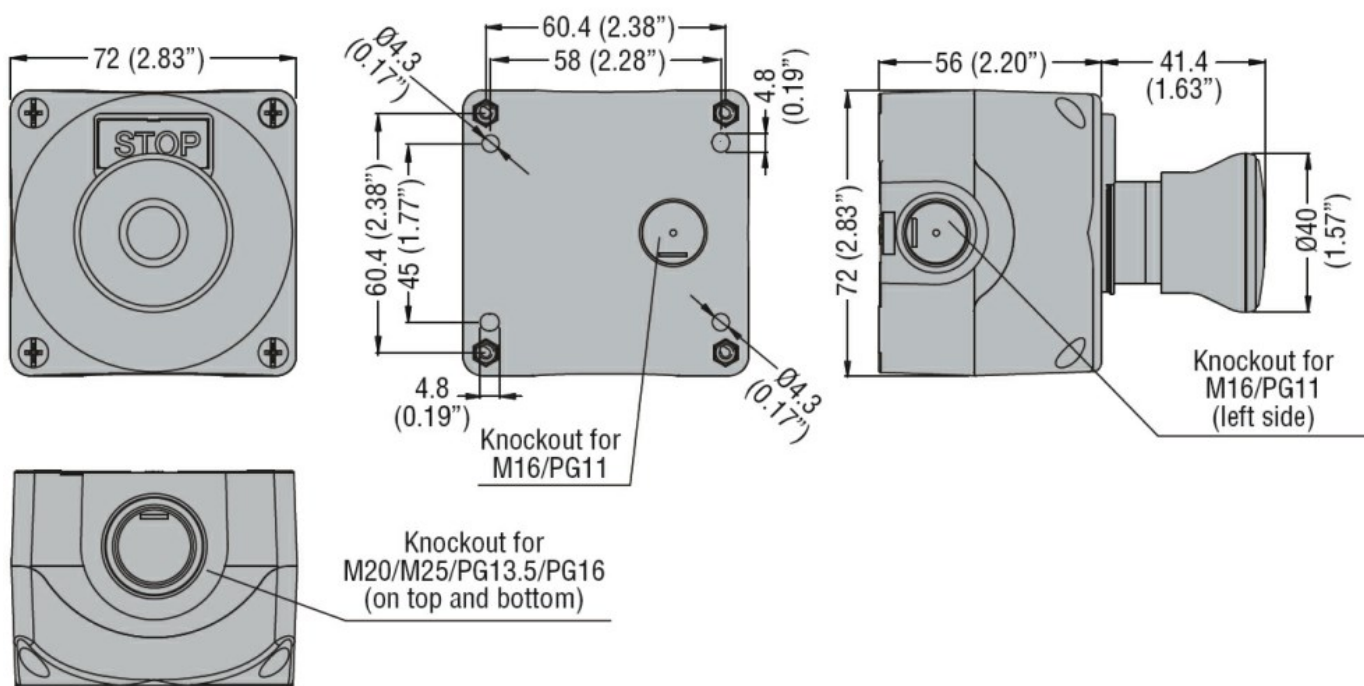

Wiring diagrams

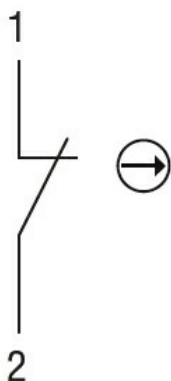

Certifications and compliance

Compliance

CSA C22.2 n° 14
IEC/EN 60947-1
IEC/EN 60947-5-1
UL508

Certificates

cULus
EAC

ETIM classification

ETIM 8.0

EC000200 -
Enclosure for
control circuit
devices