



Signal tower
Ø70mm/2.75"
LTN70

Product designation

Product type designation

General characteristics

Diameter	mm - inch	70 / 2.75
Supply voltage (DC)	V	12...24
IEC degree of protection		IP65
Power consumption	VA	1

Mechanical features

Terminals screw Spring terminals


Conductor section	AWG/Kcmil		
		min	16
		max	24
	IEC	min	mm ² 0.25
		max	mm ² 1.5

Weight g 170


Ambient conditions

Temperature	Operating temperature		
		min	°C -30
		max	°C +50

Dimensions

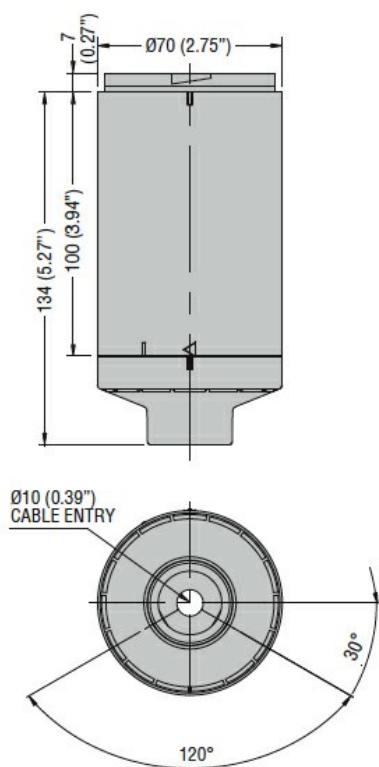

Wiring diagrams

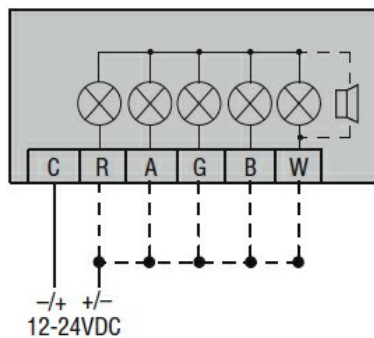

Certifications and compliance

Compliance

CSA C22.2 n° 14
IEC/EN/BS 60947-1
IEC/EN/BS 60947-5-1
UL508

Certificates

cULus

ETIM classification

ETIM 8.0

EC001154 -
Stand for signal
tower without
tube