



Product designation

Product type designation

Number of poles

Number of DIN modules

Compliance

Add-on blocks
and accessories
- 1 changeover
contact
P1X1311
1 C/O
0.5
IEC/EN/BS
60947-5-1

Electrical features

Rated impulse withstand voltage Uimp	kV	4
Rated operational voltage AC (IEC)	VAC	400
Rated current (In)	A	6
Conductivity		12V 10mA


Ambient conditions

Operating temperature	min	°C	-40
	max	°C	+70
Storage temperature	min	°C	-40
	max	°C	+80


Mechanical features

Operating position		normal allowable		Vertical plan Any
Tightening torque for terminals		min	Nm	1
		max	Nm	1
		min	lbin	0.7
		max	lbin	0.7
Terminals tool		PH2		
Conductor section				
IEC				
		max	mm²	1x 2.5 - 2x 1.5
Weight			g	40

Dimensions

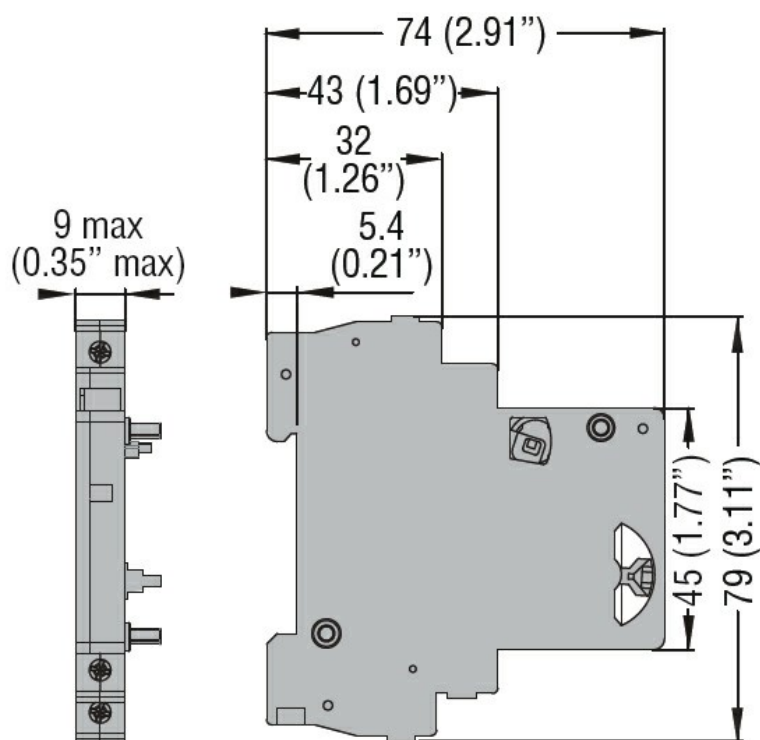

Wiring diagrams

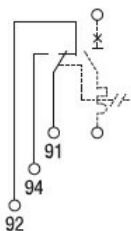

Certifications and compliance

Compliance

IEC/EN 60947-5-1.

Certifications

EAC

ETIM classification

ETIM 8.0

EC000041 -
Auxiliary contact
block