



Product designation

Engine protection controllers

Product type designation

RGK30

Power supply

Rated battery voltage

V 12/24VDC

Digital inputs

Digital input type

3 neg.+ 1 pos.

"W"/AC/PICK-UP speed inputs

"W"/AC/PICK-UP speed input type

"W"

Relay outputs

Type of output contact

2 (relay)

Mechanical features

Weight


g 160

Ambient conditions


Protection degree

IP40

Dimensions

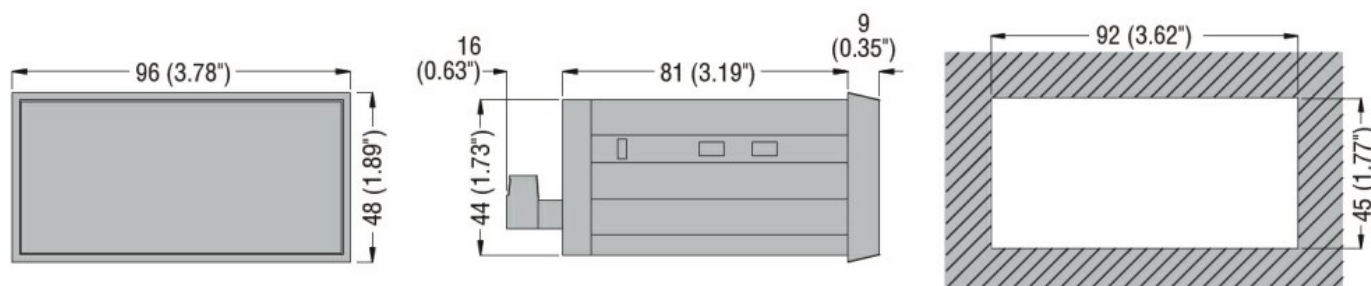

Wiring diagrams

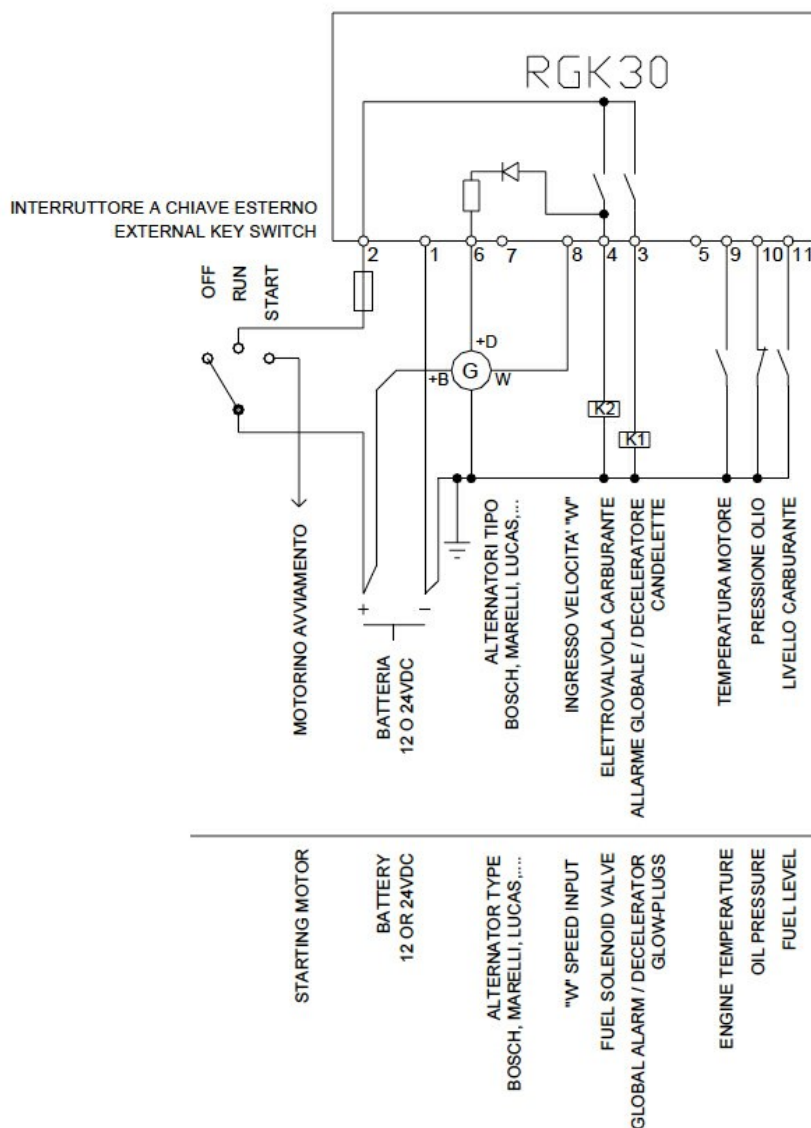

Certifications and compliance

Compliance

CSA C22.2 n° 14

EN 55011

IEC/EN 61000-6-2

IEC/EN 61010-1

UL 508

Certificates

EAC

UL Listed for USA and Canada (cULus-File E93601)

ETIM classification

ETIM 8.0

EC000236 - PLC
CPU-module