

强制性认证产品符合性自我声明



自我声明编号: 2022000302000030

Lovato Electric S.P.A. (生产者) 及洛瓦托电气贸易(上海)有限公司(生产者授权代表) 确认知晓《强制性产品认证自我声明实施规则》以及相关产品强制性认证实施规则的要求, 对本声明承担全部法律责任。

Lovato Electric S.P.A. (生产者) 及洛瓦托电气贸易(上海)有限公司(生产者授权代表) 声明以下产品已按照《强制性产品认证自我声明实施规则》以及相关产品强制性认证实施规则的要求进行检测, 符合相关标准要求; 自本声明签署之日起, 生产和销售的产品持续符合以下标准与实施规则的要求; 保存本声明涉及的技术文档至少10年; 正确使用强制性产品认证标志; 如产品或其符合性信息发生变更, 将及时更新技术文档并报送产品变更信息。

生产者名称: Lovato Electric S.P.A.
生产者地址: Via Don E. Mazza,12-24020 Gorle (Bergamo) - Italy
依据的强制性产品认证规则: CNCA-00C-008: 2019 强制性产品认证实施规则自我声明
产品名称: 凸轮开关
产品系列、型号、规格: GF;详见附件
依据的标准: GB/T14048.3-2017
生产企业名称: LOVATO KONCAR d.o.o.
生产企业地址: Borongajska cesta 81b, HR - 10000 Zagreb, Croatia

生产者联系信息

名称: Lovato Electric S.P.A.
地址: Via Don E. Mazza,12-24020 Gorle (Bergamo) - Italy
联系人: Marco Rota
电话: +390354****
电子邮箱: Marco.Rota@lovatoelectric.com
自我声明时间: 2022-05-10
自我声明地点: Gorle, Italy
指定签字人:
签章:

LOVATO ELECTRIC S.P.A.
Approvals and Standards
Service Manager

授权代表信息

名称: 洛瓦托电气贸易(上海)有限公司
地址: 上海市闵行区虹井路288号701室
联系人: 韩学刚
电话: 8621629****
电子邮箱: benjamin.han@lovatoelectric.cn
自我声明时间: 2022-05-10
自我声明地点: 上海
指定签字人:
签章:



注: 有关本声明信息真伪可登录全国认证认可信息公共服务平台 (cx.cnca.cn) 或扫描右上角二维码查询。

强制性认证产品符合性自我声明(附页)



自我声明编号: 2022000302000030

产品系列、型号、规格(附件):

额定冲击耐受电压(Uimp):4kV;
额定绝缘电压(Ui): 480V;
额定工作电压(Ue): AC480V;
约定发热电流(Ith): 10A(GF10/GF10H),20A(GF20/GF20H);
额定工作电流(Ie): 10A(GF10/GF10H),20A(GF20/GF20H);
额定限制短路电流(Iq): 3kA, 5kA, 10kA(GF10/GF10H),
3kA, 5kA, 10kA, 25kA(GF20/GF20H);
额定短时耐受电流(Icw): 250A/1s;
额定短路接通能力(Icm)(峰值): 400A(GF10/GF10H),850A(GF20/GF20H);
使用类别: AC-21A;
IP20

生产者联系信息

名称: Lovato Electric S.P.A.
地址: Via Don E. Mazza,12-24020 Gorle (Bergamo)
- Italy
联系人: Marco Rota
电话: +390354****
电子邮箱: Marco.Rota@lovatoelectric.com
自我声明时间: 2022-05-10
自我声明地点: Gorle, Italy
指定签字人:
签章:

LOVATO ELECTRIC S.P.A.
Approvals and Standards
Service Manager

授权代表信息

名称: 洛瓦托电气贸易(上海)有限公司
地址: 上海市闵行区虹井路288号701室
联系人: 韩学刚
电话: 8621629****
电子邮箱: benjamin.han@lovatoelectric.cn
自我声明时间: 2022-05-10
自我声明地点: 上海
指定签字人:
签章:



注: 有关本声明信息真伪可登录全国认证认可信息公共服务平台 (cx.cnca.cn) 或扫描右上角二维码查询。

强制性认证产品符合性自我声明(附页)



自我声明编号: 2022000302000030

产品系列、型号、规格(附件):

型号解释:

- 7 GF 10 U XXX U 28 Ntest
- A B C D E F G H
- A - LOVATO 成品号 LOVATO make-up article type (产品本体上不出现 do not show on the product)
- B - 产品系列 series
- C - 型号 rating
 - 10 - Ith = 10A, standard size 面板尺寸 30mm
 - 10H - Ith = 10A, big size 大面板尺寸 48mm
 - 20 - Ith = 20A, standard size 标准面板尺寸 48mm
 - 20H - Ith = 20A, big size 大面板尺寸 85mm
- D - U,K,D,C,E 或其他字母-为客户专属标记, 和默认标准化产品在结构和性能上完全一样。
U,K,D,C,E or other letters - special code for customer, but the same structure and function as normal product.
- 空白 blank - 表示标准化产品 standard product
- E - 接线方式 Scheme
详见《Rotary Cam Switches》, 从 00 到 999 进行编号。
Refer to Rotary Cam Switches, from 00 to 999.
- F - 安装方式 mounting way
 - U - 面板安装 Front mount
 - O - 底座安装 Rear mount
 - P - 塑料箱体 Plastic enclosure
- G - 选项 Options
 - 空白 blank - 标配 standard
 - 25 - Front mounting with red/yellow handle padlockable in 0 and protection covers 前面板安装, 带红色/黄色手柄, 0位可挂锁, 带保护盖
 - 11 - Front mounting with black handle without front plate for hole Ø22 mm fixing 前面板安装, 带黑色手柄, 无盖板, 安装孔 Ø22 mm.
 - 12 - Front mounting without front plate with key operation for hole Ø22mm fixing 前面板安装, 无盖板, 钥匙操作, 安装孔 Ø22 mm
 - 47 - Snap on front mounting with black handle for hole Ø 22mm fixing 前面板快速安装, 带黑色手柄, 安装孔 Ø 22 mm
 - 48 - Modular service cover for 35mm DIN rail mounting with black handle 35mm 导轨安装, 带维护保护罩, 带黑色手柄
 - 88 - Rear mounting with red/yellow handle padlockable in 0, door coupling and protection covers 底座安装, 带红色/黄色手柄, 0位可挂锁, 门联锁, 带保护罩
 - 4V - Front mounting with 4 screws fixing 前面板安装, 4颗螺栓固定
 - 51 - Front mounting with black handle with IP65 protection 前面板安装, 黑色手柄, 防护等级 IP65
 - 24 - Front mounting with red/yellow handle not padlockable in 0 and without protection covers 前面板安装, 带红色/黄色手柄, 0位不可挂锁, 无保护罩
 - 29 - Front mounting with front plate with key operation for hole Ø 22mm fixing: 前面板安装, 带盖板, 带钥匙, 安装孔 Ø 22mm fixing
 - 29D - Snap on front mounting with key operation for hole Ø 22mm fixing, 前面板快速安装, 带钥匙, 安装孔 Ø 22 mm
 - 06 - Front mounting with black handle padlockable in 0 前面板安装, 带黑色手柄, 0位可挂锁
 - 49 - Modular service cover for 35mm DIN rail mounting with key operation 35mm 导轨安装, 带维护保护罩, 钥匙操作
 - 2 - Switch with extended shaft. Extension of 100mm 带延长杆, 长度 100mm
 - 05 - Switches with locking. In standard manner locking is in "0"-possible in other position, too The

生产者联系信息

名称: Lovato Electric S.P.A.
地址: Via Don E. Mazza,12-24020 Gorle (Bergamo) - Italy
联系人: Marco Rota
电话: +390354****
电子邮箱: Marco.Rota@lovatoelectric.com
自我声明时间: 2022-05-10
自我声明地点: Gorle, Italy
指定签字人:
签章: **LOVATO ELECTRIC S.P.A.**

Approvals and Standards
Service Manager

授权代表信息

名称: 洛瓦托电气贸易(上海)有限公司
地址: 上海市闵行区虹井路288号701室
联系人: 韩学刚
电话: 8621629****
电子邮箱: benjamin.han@lovatoelectric.cn
自我声明时间: 2022-05-10
自我声明地点: 上海
指定签字:
签章: **LOVATO ELECTRIC (SHANGHAI) CO., LTD.**

注: 有关本声明信息真伪可登录全国认证认可信息公共服务平台 (cx.cnca.cn) 或扫描右上角二维码查询。

强制性认证产品符合性自我声明(附页)



自我声明编号: 2022000302000030

产品系列、型号、规格(附件):

- key can be pulled out only in locked position 带锁“O”位锁闭, 可以定义其他位置锁闭, 钥匙仅在位置 O 可以拔出。
- 23 - Switch with padlock. Main switch - black handle and front plate 开关带锁, 主开关——黑色手柄和面板
- 09 - Rotary cam switch with handle and nut. Mounting in Ø30 mm 凸轮开关带手柄和螺母, Ø30 mm.
- 10 - Rotary cam switch with key and nut. Mounting in Ø30 mm. Locking and pull-out of the key at 90° 凸轮开关带钥匙和螺母, Ø30 mm, 90°位置锁闭和钥匙拔出
- 15 - Mounting with a signal lamp 带信号指示灯
- 16 - Blockade of positions two hands operating. Without locking and aux contacts 双侧操作锁闭, 不带锁和辅助触点
- 26 - Blockade of positions two hands operating. Locking by one padlock 双侧操作锁闭, 挂锁锁闭
- 17 - Blockade of positions two hands operating. One pair of aux contacts INO + INC 双侧操作锁闭, 一对常开常闭辅助触点
- 27 - Locking by one padlock. One pair of aux contacts INO + INC 挂锁锁闭, 一对常开常闭辅助触点
- 18 - Mounting on the rail. Mounting on the rail 35 EN 50022. 导轨安装, 35mm 导轨 EN50022
- 20 - Rotary cam switch with handle and front plate. Mounting into Ø22 mm or Ø30 mm, with two screws 凸轮开关, 带手柄和面板, 安装孔 Ø22 mm 或 Ø30 mm, 两颗螺丝
- 28 - Interlocking of anticlockwise rotation 逆时针旋转互锁
- 29K - Rotary cam switch with key. Quick mounting in Ø 22 mm, switch without front plate 凸轮开关, 带钥匙, 快速安装, 安装孔 Ø 22 mm, 无面板
- 31 - Mounting with four inserted nuts M4 带 4 个 M4 内置螺母
- 39D - Mounting with two screws (distance 28 mm) 两个螺丝安装 (间距 28mm)
- 39T - Mounting with two screws (distance 30 mm) 两个螺丝安装 (间距 30mm)
- 41 - Rotary cam switch with locking 凸轮开关, 带锁
- 41D - Rotary cam switch with locking. Quick mounting into Ø 22 mm, switch with front plate, lockable handle 凸轮开关, 带锁, 快速安装, 安装孔 Ø 22 mm, 带面板, 手柄挂锁。
- 41K - Rotary cam switch with locking. Quick mounting into Ø 22 mm, lockable handle, switch without front plate 凸轮开关, 带锁, 快速安装, 安装孔 Ø 22 mm, 不带面板, 手柄挂锁。
- 46 - Rotary cam switch with handle and front plate. Quick mounting in Ø 16 mm 凸轮开关, 带手柄和面板, 快速安装, 安装孔 Ø 16 mm
- 48D - Snap on base mounting for the rail 35 EN 50022. Both the service cover and handle are fixed measure: 35mm 导轨安装, 带护罩 (45mm) 和固定长度手柄
- 56 - Switch with padlock. The same colour of handle and front plate 带锁, 手柄和面板同色
- 73 - Switch with padlock. Main switch - black handle and front plate 带锁, 黑色手柄和面板
- 75 - Switch with padlock. Main switch with emergency - red handle, yellow front plate 带锁, 主开关, 急停, 红色手柄, 黄色面板
- 57 - Door coupling. Door opening in any position. Mounting with 4 screws 门互锁开关, 门可在任意位置打开, 4 颗螺丝安装
- 57D - Door coupling. Door opening in any position. Mounting with 2 screws 门互锁开关, 门可在任意位置打开, 2 颗螺丝安装
- 58 - Door coupling. Door opening in position "O". Mounting with 4 screws 门互锁开关, 门可在位置 O 打开, 4 颗螺丝安装
- 58D - Door coupling. Door opening in position "O". Mounting with 2 screws 门互锁开关, 门可在位置 O 打开, 2 颗螺丝安装
- 66 - Rotary cam switch without front plate. Quick mounting into Ø 16 mm 凸轮开关, 不带面板, 快速安装, 安装孔 Ø 16 mm
- 67 - Rotary cam switch without front plate. Quick mounting into Ø 22 mm 凸轮开关, 不带面板, 快速安装, 安装孔 Ø 22 mm
- 71 - Push and turn. Quick mounting into Ø 22 mm 压下旋转, 快速安装, 安装孔 Ø 22 mm
- 72 - Push and turn. Quick mounting into Ø 30 mm 压下旋转, 快速安装, 安装孔 Ø 30 mm
- 85 - Door coupling switch with padlock. Padlocking (1-3) only in "O" - door opening in position "O". The


生产者联系信息

名称: Lovato Electric S.P.A.
地址: Via Don E. Mazza, 12-24020 Gorle (Bergamo) - Italy
联系人: Marco Rota
电话: +390354****
电子邮箱: Marco.Rota@lovatoelectric.com
自我声明时间: 2022-05-10
自我声明地点: Gorle, Italy
指定签字人:
签章:

LOVATO ELECTRIC S.P.A.
Approvals and Standards
Service Manager

授权代表信息

名称: 洛瓦托电气贸易(上海)有限公司
地址: 上海市闵行区虹井路288号701室
联系人: 韩学刚
电话: 8621629****
电子邮箱: benjamin.han@lovatoelectric.cn
自我声明时间: 2022-05-10
自我声明地点: 上海
指定签字:
签章:

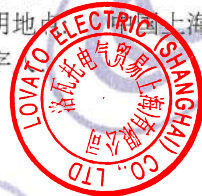

注: 有关本声明信息真伪可登录全国认证认可信息公共服务平台 (cx.cnca.cn) 或扫描右上角二维码查询。

强制性认证产品符合性自我声明(附页)



自我声明编号: 2022000302000030

产品系列、型号、规格(附件):

- same colour of handle and front plate 门互锁开关, 带锁, 挂锁 (1-3) 仅在 O 位置门可以打开, 手柄和面板同色
- 86 - Door coupling switch with padlock; Padlocking (1-3) only in "O" - door opening in position "O". Red handle, yellow front plate 门互锁开关, 带锁, 挂锁 (1-3) 仅在 O 位置门可以打开, 红色手柄, 黄色面板
- 98 - Door coupling main switch with emergency off; Padlocking (1-3) only in "O" - door opening in position "O" 门互锁开关, 急停, 挂锁 (1-3) 仅在 O 位置门可以打开。
- 102 - Extension shaft and door coupling. Shaft 100 mm 带 100mm 延长杆, 门互锁
- 102-200 - Extension shaft and door coupling. Shaft 200 mm (for GF20H) 用于 GF20H, 带 200mm 延长杆, 门互锁
- 108 - Extension shaft and door coupling. Door opening in position "O", standard version with one module 带延长杆, 门互锁, 门在位置 O 打开, 标准带第一模块
- 108D-2 - Extension shaft and door coupling. Door opening in position "O", with two module 带延长杆, 门互锁, 门在位置 O 打开, 带两个模块
- 108D-3 - Extension shaft and door coupling. Door opening in position "O", with three modules 带延长杆, 门互锁, 门在位置 O 打开, 带三个模块
- 108D-4 - Extension shaft and door coupling. Door opening in position "O", with four modules 带延长杆, 门互锁, 门在位置 O 打开, 带四个模块

H - 面板字符 (以字母 N 开头), 默认空白 title of the front panel ("N" is required), default is blank.

注: GF20U178U = GF2090U + 客户定制化面板图样, 实物结构和功能与 GF2090U 完全相同。
Note: GF20U178U = GF2090U + customized label, same structure and function as GF2090U.


生产者联系信息

名称: Lovato Electric S.P.A.
地址: Via Don E. Mazza, 12-24020 Gorle (Bergamo) - Italy
联系人: Marco Rota
电话: +390354****
电子邮箱: Marco.Rota@lovatoelectric.com
自我声明时间: 2022-05-10
自我声明地点: Gorle, Italy
指定签字人:
签章:

LOVATO ELECTRIC S.P.A.
Approvals and Standards
Service Manager

授权代表信息

名称: 洛瓦托电气贸易(上海)有限公司
地址: 上海市闵行区虹井路288号701室
联系人: 韩学刚
电话: 8621629****
电子邮箱: benjamin.han@lovatoelectric.cn
自我声明时间: 2022-05-10
自我声明地点: 中国上海
指定签字人:
签章:

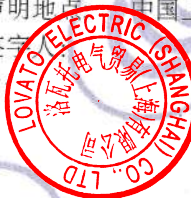

注: 有关本声明信息真伪可登录全国认证认可信息公共服务平台 (cx.cnca.cn) 或扫描右上角二维码查询。