



Product designation  
Product type designation

Probe  
SCM

#### Connections

Terminals type

Threaded rod  
with nut

#### Ambient conditions

Temperature

Operating temperature

max °C +100

Maximum operating pressure


bar 10

#### Housing

Weight

g 115

#### Dimensions

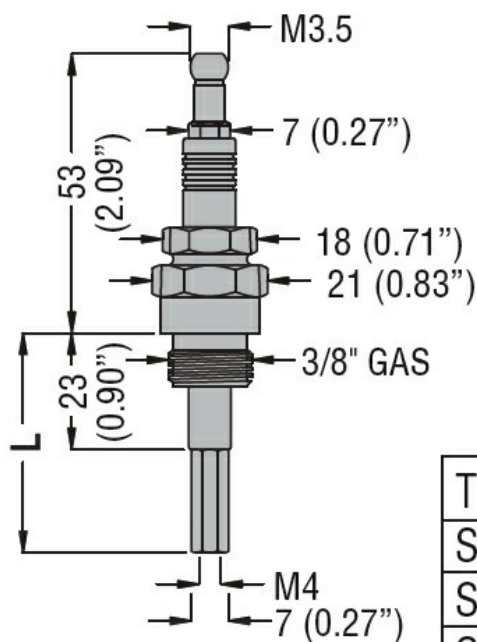

TYPE	L
SCM04	43 (1.69'')
SCM50	500 (19.68'')
SCM100	1000 (39.37'')

#### Certifications and compliance

Compliance

/

Certificates

EAC

#### ETIM classification

ETIM 8.0

EC010106 -  
Liquid level  
sensor