




Number of poles	Nr.	1
Operating voltage type		AC
Contact characteristics		
IEC Conventional free air thermal current Ith	A	40
Mechanical features		
Tightening torque for terminals	min	Nm 1.8
	max	Nm 2
	min	Ibin 16
	max	Ibin 18


Dimensions

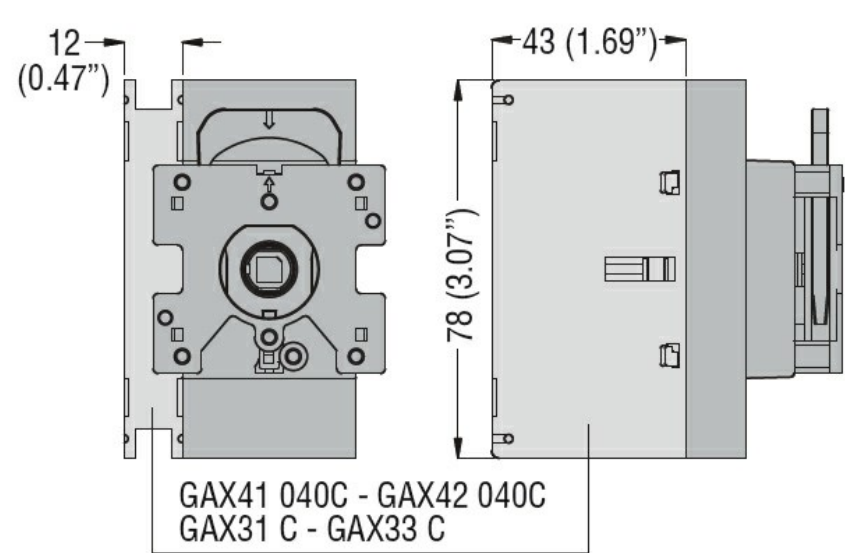

Wiring diagrams

Fourth pole add on

GAX42... GAX41...

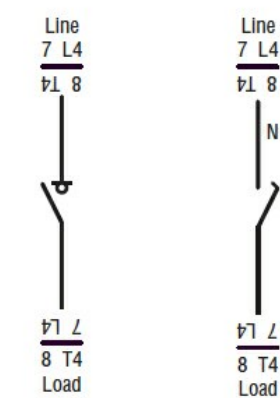

Certifications and compliance

Compliance

CSA C22.2

IEC/EN 60947-1

IEC/EN 60947-3

UL508

UL98

Certifications

CCC

CSA C22.2 n°14

cULus according to UL508

EAC

ETIM classification

ETIM 8.0

EC002498 -
Accessories/spare
parts for low-
voltage switch
technology