




|                                           |  |        |                                          |     |
|-------------------------------------------|--|--------|------------------------------------------|-----|
| Product designation                       |  |        | Pushbutton<br>actuator, spring<br>return |     |
| Product type designation                  |  |        | LPCB10                                   |     |
| General characteristics                   |  |        |                                          |     |
| Colour                                    |  |        | Black                                    |     |
| Type of positions                         |  |        | Flush pushbutton                         |     |
| Material                                  |  |        | Polyamide                                |     |
| IEC degree of protection                  |  |        | IP66, IP67 and<br>IP69K                  |     |
| Mechanical features                       |  |        |                                          |     |
| Operating force                           |  | kg-lb  | <0.5Kg / 1.1lb                           |     |
| Mechanical life - spring return actuators |  | cycles | 5000000                                  |     |
| Fixing                                    |  |        | Without mounting<br>adapter              |     |
| Mounting adapter                          |  |        | LPXAU120                                 |     |
| Weight                                    |  | g      | 25                                       |     |
| UL technical data                         |  |        |                                          |     |
| UL degree of protection                   |  |        | Type1, 2, 3R, 4,<br>4X, 12, 12K          |     |
| Ambient conditions                        |  |        |                                          |     |
| Temperature                               |  |        |                                          |     |
| Operating temperature                     |  | min    | °C                                       | -25 |
|                                           |  | max    | °C                                       | +70 |
| Storage temperature                       |  | min    | °C                                       | -40 |
|                                           |  | max    | °C                                       | +85 |

## Dimensions

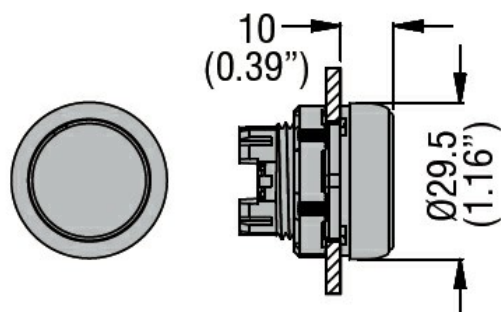

## Certifications and compliance

### Compliance

CSA C22.2 n° 14  
IEC/EN/BS 60947-1  
IEC/EN/BS 60947-5-1  
UL508

---

Certificates

CCC

cULus

EAC

RINA

ETIM classification

ETIM 8.0

EC000221 -  
Front element for  
push button