


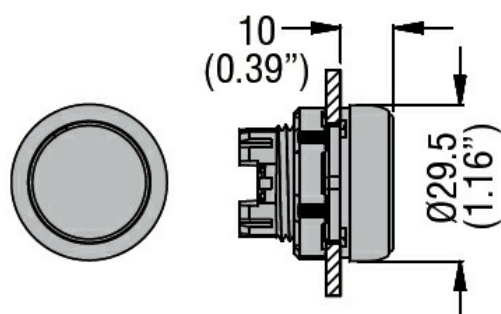

Product designation			Pushbutton actuator, spring return	
Product type designation			LPCB10	
General characteristics				
Colour			Green	
Type of positions			Flush pushbutton	
Material			Polyamide	
IEC degree of protection			IP66, IP67 and IP69K	
Mechanical features				
Operating force		kg-lb	<0.5Kg / 1.1lb	
Mechanical life - spring return actuators		cycles	5000000	
Fixing		Without mounting adapter		
Mounting adapter		LPXAU120		
Weight		g	25	
UL technical data				
UL degree of protection		Type1, 2, 3R, 4, 4X, 12, 12K		
Ambient conditions				
Temperature				
Operating temperature				
		min	°C	-25
		max	°C	+70
Storage temperature				
		min	°C	-40
		max	°C	+85
Dimensions				



<b>Certifications and compliance</b>	
Compliance	
CSA C22.2 n° 14	
IEC/EN/BS 60947-1	
IEC/EN/BS 60947-5-1	
UL508	

---

Certificates

CCC

cULus

EAC

RINA

ETIM classification

ETIM 8.0

EC000221 -  
Front element for  
push button