



Product designation  
Product type designation

SOCKET  
HR5XS22

#### Contact characteristics

Rated insulation voltage $U_i$ IEC/EN	V	250
Rated impulse withstand voltage $U_{imp}$	kV	4

#### Mechanical features

Socket screw tightening tool (cross / flat blade)	Phillips 1/4.5mm
---	------------------

Conductor section

AWG/Kcmil

min	20
max	14


IEC

min	mm <sup>2</sup>	0.5
max	mm <sup>2</sup>	2.5

Fixing


On 35mm DIN  
rail and with  
screw

#### Dimensions

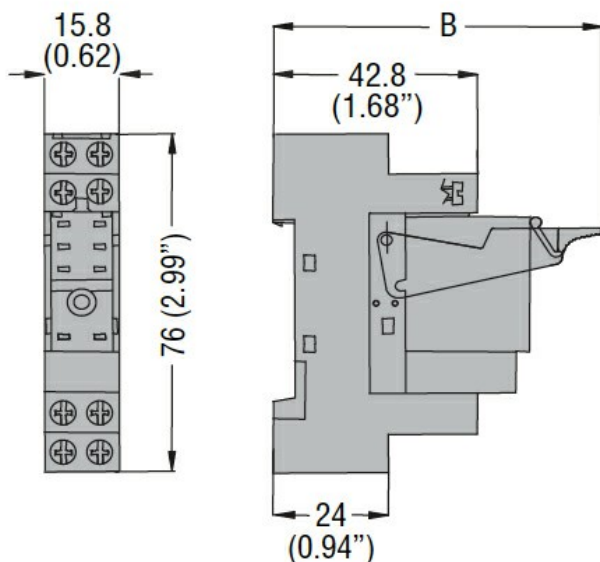

B: 72.5mm (2.85") con HR3X88  
82.5mm (3.25) con XR5X88

#### Wiring diagrams

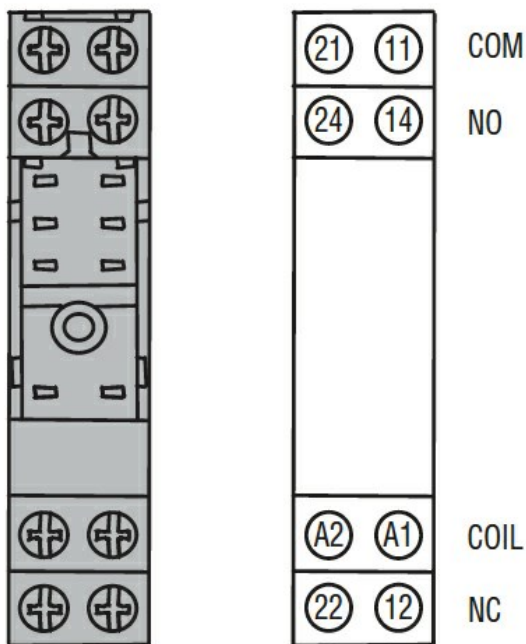

Certifications and compliance

Compliance	IEC/EN 61810
Certificates	CSA
	cULus
	cURus
	EAC

ETIM classification

ETIM 8.0	EC001456 - Relay socket
----------	-------------------------