




Product designation			Current trasformers		
Product type designation			DM0T0080		
Type of CT			Solid-core		
Current inputs					
Primary current Ipn (/5)			A	80	
Operational frequency			min	Hz	50
			max	Hz	60
Secondary output current			A	5	
Overload withstand Ipn			%	120	
Burden			cl. 1	VA	1.5
Insulations					
Rated insulation voltage Ui IEC/EN			V	720	
IEC rated short-time thermal current Ith			Ith for s	40...60	
IEC rated dynamic current Idyn			Ith for s	2.5	
Insulation dry type			Class E		
Mechanical features					
Terminals type			Screw		
Fixing			DIN rail or by Screw		
Weight			g	200	
Ambient conditions					
Temperature			Operating temperature		
			min	°C	-25
			max	°C	+50
Storage temperature			min	°C	-40
			max	°C	+80
Relative humidity			%	90	
Protection degree			IP30		
Dimensions					

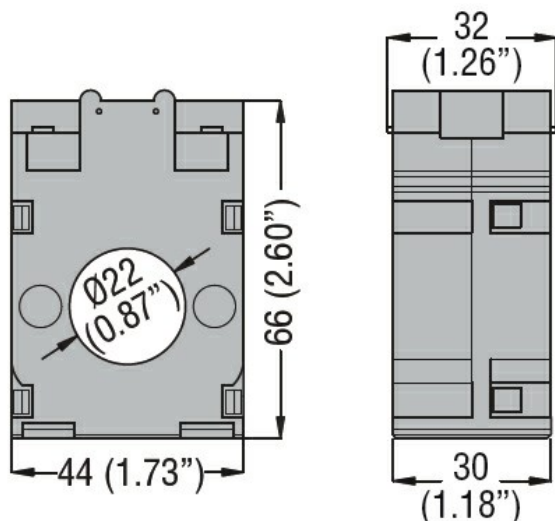

Certifications and compliance

Certifications

IEC/EN/BS 61869-1

IEC/EN/BS 61869-2

Compliance

EAC

ETIM classification

EC000066 - Power contactor, AC switching

□