



Product designation

SOCKET

Product type designation

HR5XS21S

### Contact characteristics

Rated insulation voltage  $U_i$  IEC/EN

V 250

Rated impulse withstand voltage  $U_{imp}$

kV 4

### Mechanical features

Socket screw tightening tool (cross / flat blade)

Phillips 1/4.5mm

Conductor section

AWG/Kcmil

min 20

max 14

IEC


min mm<sup>2</sup> 0.5

max mm<sup>2</sup> 2.5

Fixing

On 35mm DIN  
rail


### Dimensions

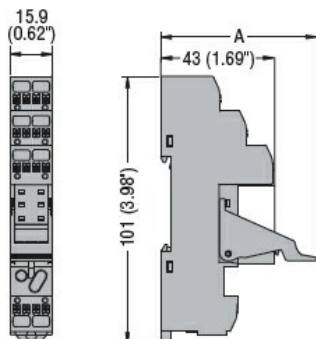

A: 60mm (2.36") with HR3X88

70mm (2.75") with XR5X88

### Wiring diagrams

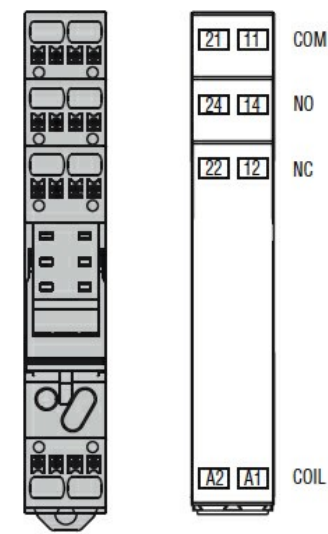

Certifications and compliance

Compliance	IEC/EN 61810
Certificates	CSA
	cURus
	EAC

ETIM classification

ETIM 8.0	EC001456 - Relay socket
----------	-------------------------