





Product designation				Signal tower
Product type designation				Ø45mm/1.7"
				8TL4
General characteristics				
Diameter			mm - inch	45 / 1.77
Supply voltage (DC)			V	24±10%
Colour			White, green, blue, orange, red	
IEC degree of protection			IP54	
Light consumption per module (DC)			mA	37
Mechanical features				
Tightening torque for terminals max			Nm	0.5
Terminals screw			Screw clamp terminals	
Conductor section				
AWG/Kcmil		max		16
IEC		max		mm²
				1.5
Weight			g	400
Ambient conditions				
Temperature				
Operating temperature		min		°C
		max		°C
Dimensions				

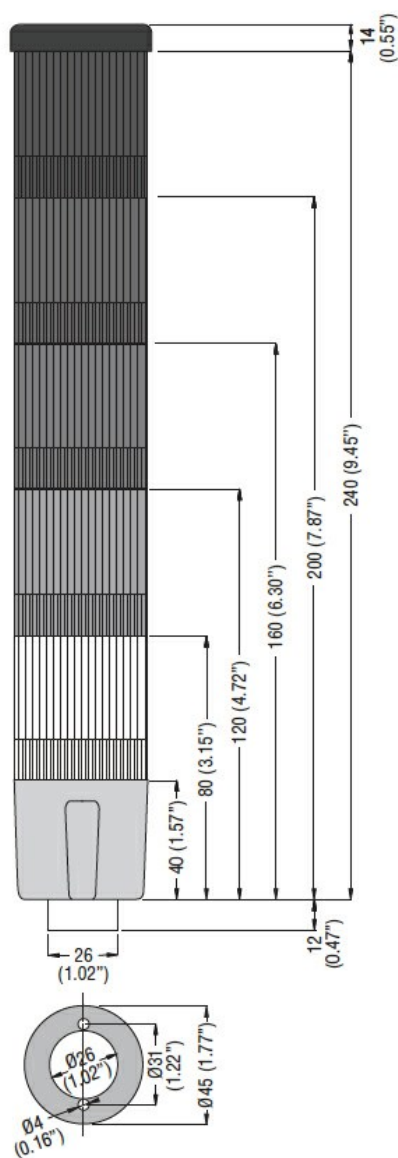

Wiring diagrams

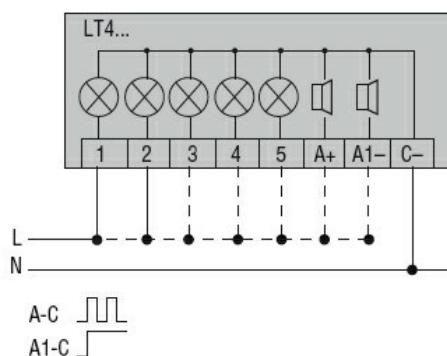

Certifications and compliance

Compliance

CSA C22.2 n° 14

IEC/EN 60947-1

IEC/EN 60947-5-1

UL508

Certificates

cULus

EAC

ETIM classification

ETIM 8.0

EC001042 -
Signal tower
complete