



Mushroom head
pushbutton,
Latch, turn to
release Ø
40mm/1.6"
LPSB664

Product designation

Product type designation

General characteristics

Colour	Red
Material	Aluminium and zinc alloy for metal parts and polyamide for plastic parts
IEC degree of protection	IP66, IP67 and IP69K

Mechanical features

Fixing	Without mounting adapter
Mounting adapter	LPXAU120M

UL technical data

UL degree of protection	Type1, 2, 3R, 4, 4X, 12, 12K
-------------------------	------------------------------

Ambient conditions

Temperature


Operating temperature

min	°C	-25
max	°C	+70

Storage temperature

min	°C	-40
max	°C	+85

Dimensions

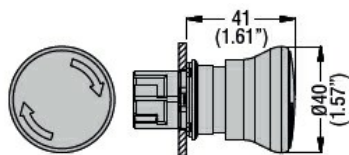

Certifications and compliance

Compliance

CSA C22.2 n° 14
IEC/EN/BS 60947-1
IEC/EN/BS 60947-5-1
UL508

Certificates

cULus

ETIM classification

TLAČÍTKOVÝ OVLADAČ S HŘIBOVÝM KNOFLÍKEM, KOVOVÁ ŘADA Ø22MM PLATINUM,
UVOLNIT OTOČENÍM, ČERVENÝ OVLADAČ Ø40MM PRO BEZP. STOP ISO 13850

ETIM 8.0

EC000221 -
Front element for
push button