





Product designation	Engine protection controllers	
Product type designation	RGK30	
Power supply		
Rated battery voltage	V	12/24VDC
Digital inputs		
Digital input type	3 neg.+ 1 pos.	
"W"/AC/PICK-UP speed inputs		
"W"/AC/PICK-UP speed input type	"W"	
Relay outputs		
Type of output contact	2 (relay)	
Mechanical features		
Weight	g	160
Ambient conditions		
Protection degree	IP40	
Dimensions		

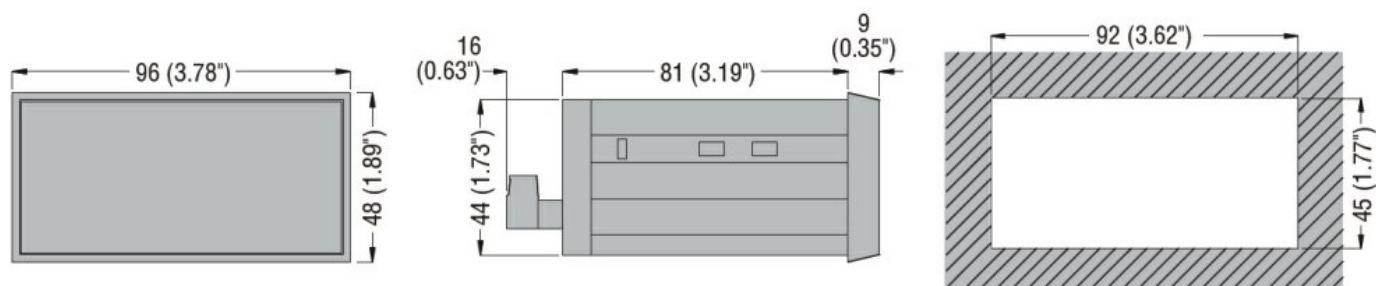

Wiring diagrams

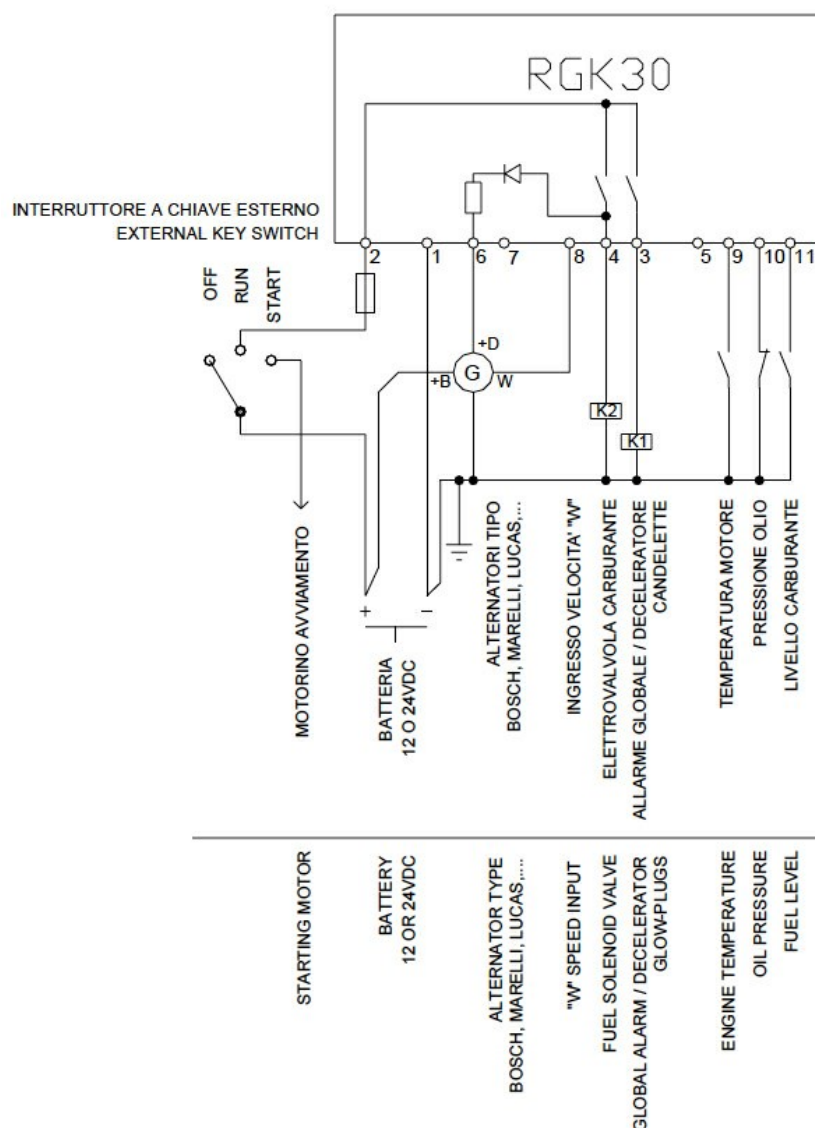

Certifications and compliance

Compliance

CSA C22.2 n° 14

EN 55011

IEC/EN 61000-6-2

IEC/EN 61010-1

UL 508

Certificates

EAC

UL Listed for USA and Canada (cULus-File E93601)

ETIM classification

ETIM 8.0

EC000236 - PLC
CPU-module