




|                                               |                          |                       |
|-----------------------------------------------|--------------------------|-----------------------|
| Product designation                           | Power distribution block |                       |
| Electrical features                           |                          |                       |
| Number of poles                               |                          | 4                     |
| Rated insulation voltage Ui                   | V                        | 500                   |
| IEC Conventional free air thermal current Ith | A                        | 100                   |
| Rated peak withstand current Ipk              | kA                       | 20                    |
| Rated short time current Icw 60s              | A                        | 4.5                   |
| Connections                                   |                          |                       |
| Terminal hole diameter_Option 1               | mm                       | 2x8.5mm               |
| Conductor section connectable_Option 1        | mm2                      | 10...25               |
| Terminal hole diameter_Option 2               | mm                       | 5x5.5mm               |
| Conductor section connectable_Option 2        | mm2                      | 2.5...6               |
| Terminal hole diameter_Option 3               | mm                       | 4x4.5mm               |
| Conductor section connectable_Option 3        | mm2                      | 1.5...4               |
| Mechanical features                           |                          |                       |
| Operating position                            | normal allowable         | Vertical plane Any    |
| Fixing                                        |                          | Screw / DIN rail 35mm |
| Phillips                                      |                          | 2                     |
| Weight                                        | g                        | 345                   |
| Resistance & Protection                       |                          |                       |
| Terminals IP degree                           |                          | IP20 front            |
| Dimensions                                    |                          |                       |

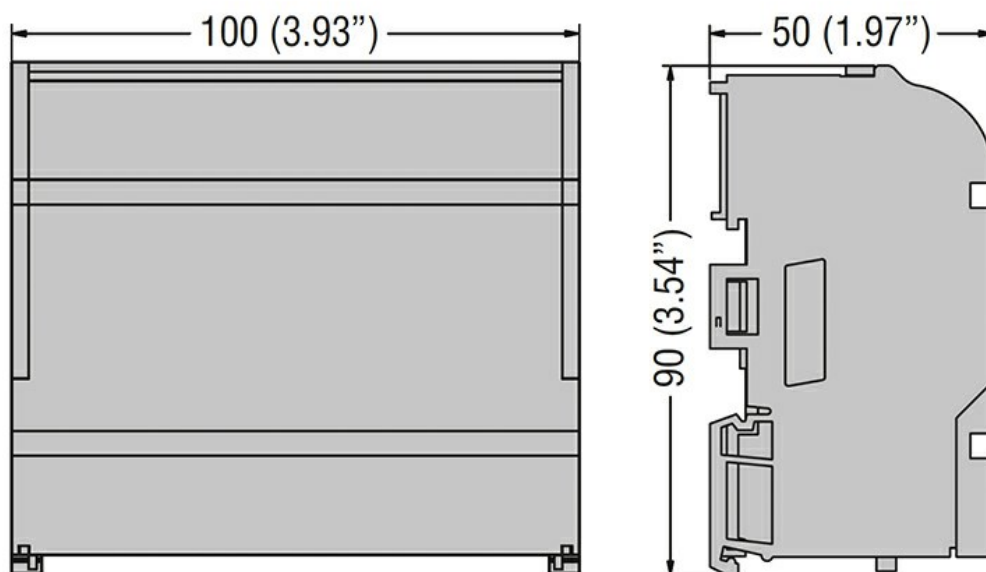

#### Certifications and compliance

##### Certifications

IEC/EN/BS 60947-7-1

##### Compliance

TÜV

#### ETIM classification

EC000066 - Power contactor, AC switching