



Product designation

Product type designation

Type of CT

Current
transformers
DM0TW0005
Wound primary

Current inputs

Primary current I_{pn} (/5)	A	5
Operational frequency	min max	Hz Hz 50 60
Secondary output current	A	5
Overload withstand I_{pn}	%	120
Burden	cl. 1 VA	3.75

Insulations

IEC rated short-time thermal current I_{th}	I_{th} for s	40...60
IEC rated dynamic current I_{dyn}	I_{th} for s	2.5
Insulation dry type		Class E


Mechanical features

Terminals type		Screw
Fixing		DIN rail or by Screw
Weight	g	296

Ambient conditions

Temperature	Operating temperature	min max	°C °C -25 +50
	Storage temperature	min max	°C °C -40 +80
Relative humidity		%	90
Protection degree			IP30

Dimensions

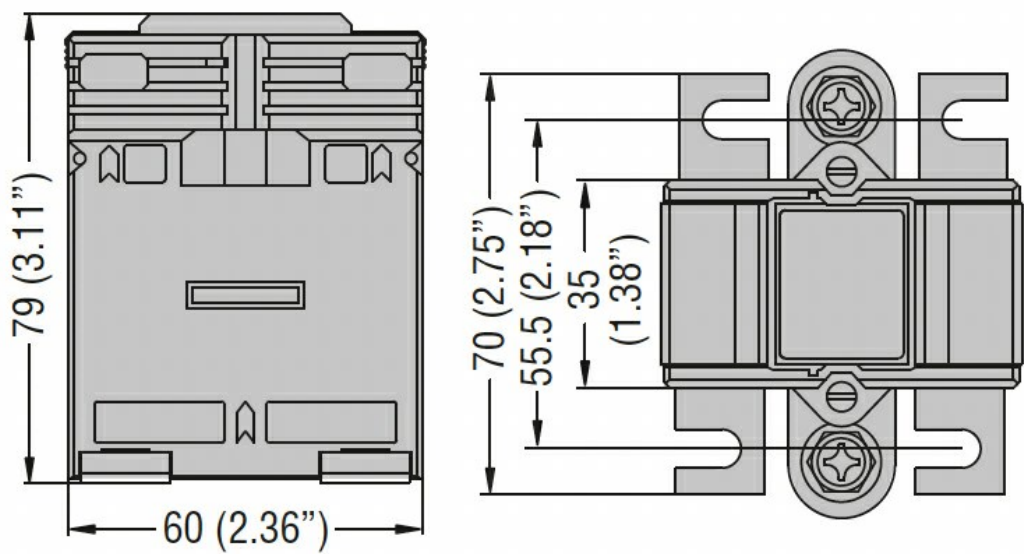

Certifications and compliance

Certifications	IEC/EN/BS 61869-1
	IEC/EN/BS 61869-2
Compliance	CE
	EAC
	UKCA

ETIM classification

EC000066 - Power contactor, AC switching