




Product designation	Empty enclosures		
Product type designation	M2N		
Electrical features			
Maximum operating current (≤440V)	A	32	
Components			
Contactor standard supplied			BF25A, BF26A, BF32A
Thermal relay to purchase separately			RF38
Mechanical features			
Weight	g	640	
Ambient conditions			
Operating temperature	min	°C	-25
	max	°C	+60
Storage temperature	min	°C	-40
	max	°C	+70
Resistance & Protection			
Frontal IP degree			IP65
Dimensions			

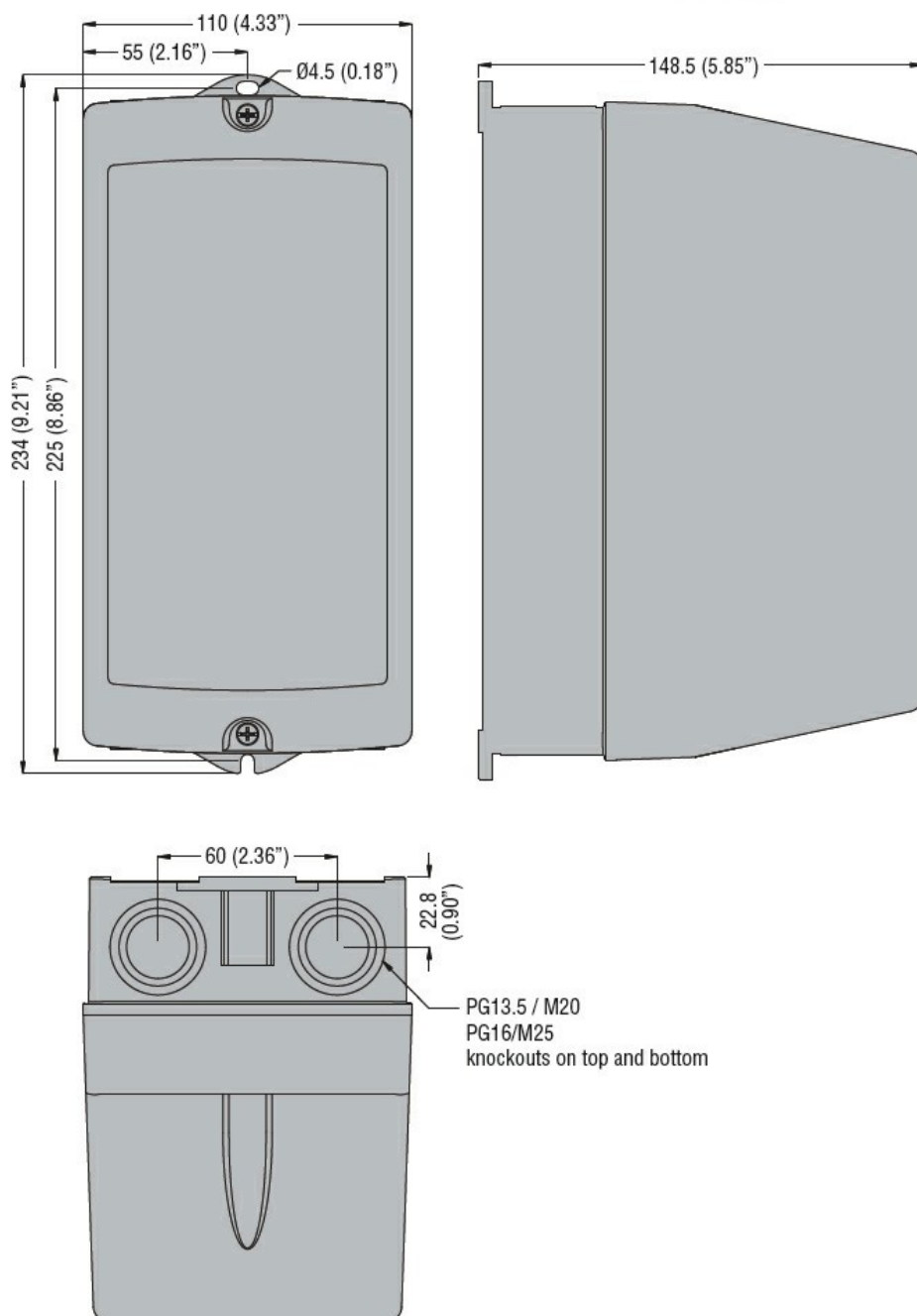

## Certifications and compliance

### Compliance

CSA C22.2 n° 14

IEC/EN 60947-1

IEC/EN 60947-4-1

UL508

### Certificates

cULus

## ETIM classification

ETIM 8.0

EC000200 -  
Enclosure for  
control circuit  
devices