



Product designation

Product type designation

Operating voltage type

Number of DIN modules

Safety
transformer
CTRS
AC
3

Electrical features

| | | |
|----------------------|-----|---------|
| Output power | VA | 25 |
| Supply voltage | VAC | 230 |
| Rated output voltage | VAC | 12...24 |

Control circuit

| | |
|--------------------------------------|--------|
| Auxiliary rated supply voltage U_s | 230VAC |
|--------------------------------------|--------|

Ambient conditions

| | | | |
|-----------------------|-----|----|-----|
| Operating temperature | min | °C | -10 |
| | max | °C | +25 |
| Storage temperature | min | °C | -40 |
| | max | °C | +70 |

Mechanical features


| | | | |
|---------------------------------|-----|----|---|
| Tightening torque for terminals | max | Nm | 1 |
|---------------------------------|-----|----|---|

| | | | |
|-------------------|----------------|-----------------|-----|
| Conductor section | Power terminal | | |
| | min | mm ² | 0.5 |
| | max | mm ² | 10 |


| | |
|----------------|----|
| Terminals tool | M4 |
|----------------|----|

| | | |
|--------|---|-----|
| Weight | g | 582 |
|--------|---|-----|

Dimensions

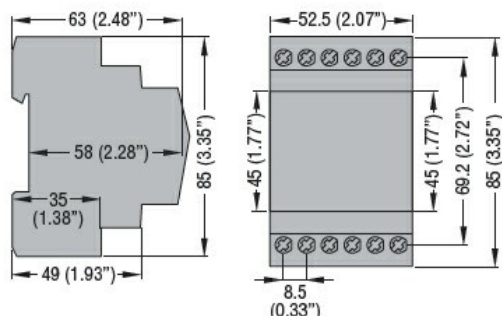

Wiring diagrams

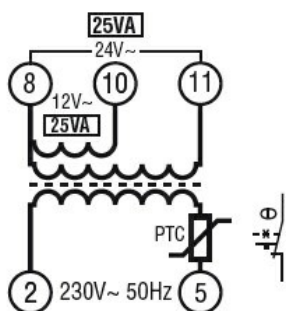

Certifications and compliance

Compliance

IEC/EN 61558-2-8

ETIM classification

ETIM 8.0

EC002486 -
One-phase
control
transformer