





Product designation			Remote display unit	
Product type designation			EXCRDU1	
General characteristics				
Description			Remote display unit, graphic LCD, touch screen 128x112 pixels, IP65 protection. Compatible with ADXL... soft starter and VLB3... variable speed drives	
Functions			Remote display unit	
Rated power supply voltage			Auxiliary supply 100...240VAC/12...24VDC	
Interface				
RS485 communication			Yes	
Mechanical features				
Conductor cross section			min	mm ² 0.2
			Max	mm ² 2.5
			min	AWG 24 / 18 for UL/CSA
			Max	AWG 12
Tightening torque (Max)			Nm	0.56
			lbin	4.5
Dimensions				

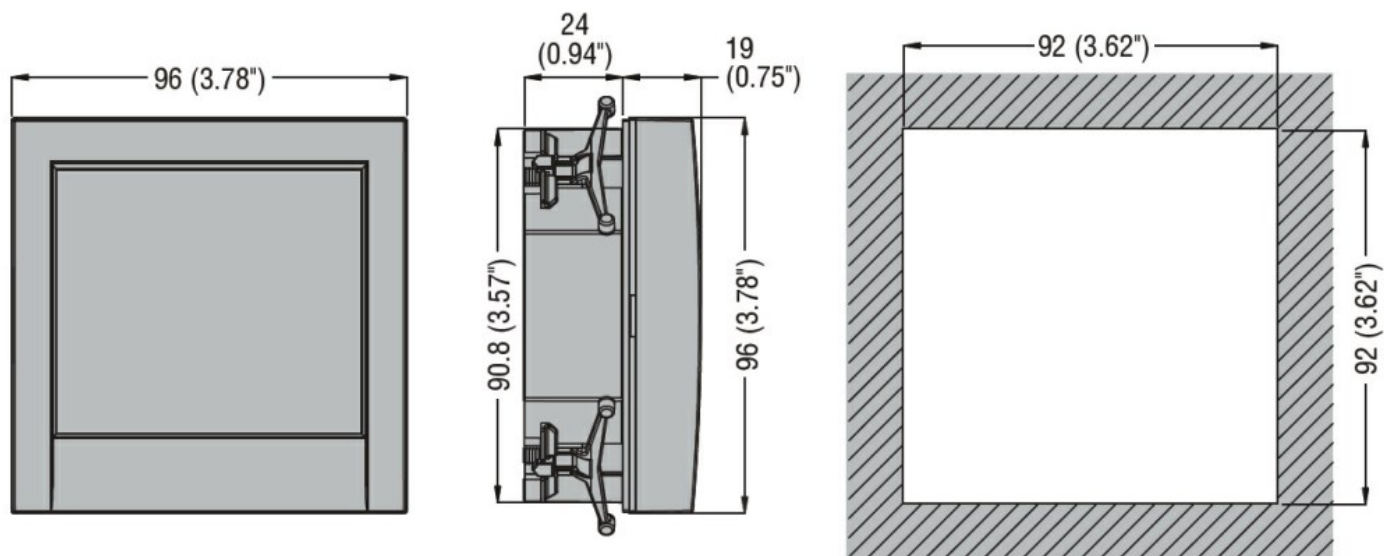

Wiring diagrams

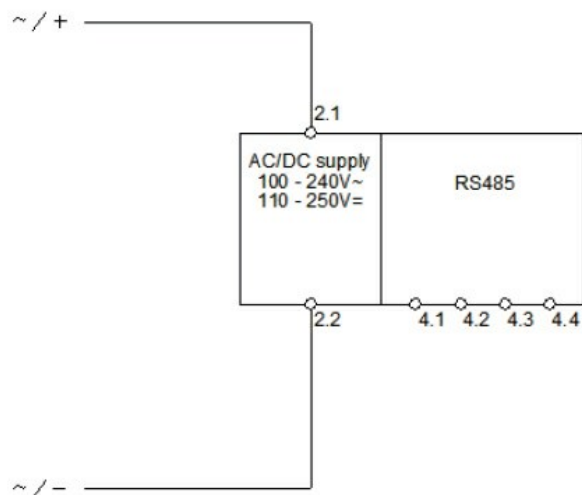

Certifications and compliance

Compliance

C22.2-n°14-95

IEC/EN 61000-6-2

IEC/EN 61000-6-4

UL508

Certificates

cULus

EAC

ETIM classification

ETIM 8.0

EC002498 -
Accessories/spare
parts for low-
voltage switch
technology