





Product designation			SOCKET	
Product type designation			HR5XS21	
Contact characteristics				
Rated insulation voltage Ui IEC/EN			V	250
Rated impulse withstand voltage Uimp			kV	4
Mechanical features				
Socket screw tightening tool (cross / flat blade)			Phillips 1/4.5mm	
Conductor section				
AWG/Kcmil		min		20
		max		14
IEC		min		mm² 0.5
		max		mm² 2.5
Fixing			DIN rail or with screws	

Dimensions

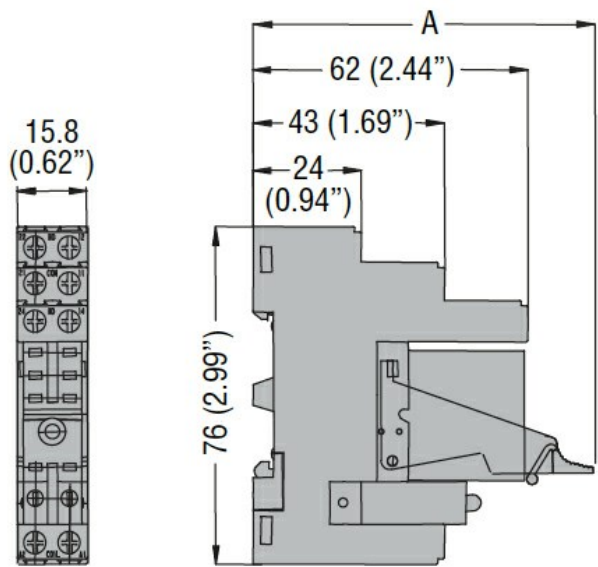

A: 65mm (2.56") con HR3X88
75mm (2.95") con XR5X88

Wiring diagrams

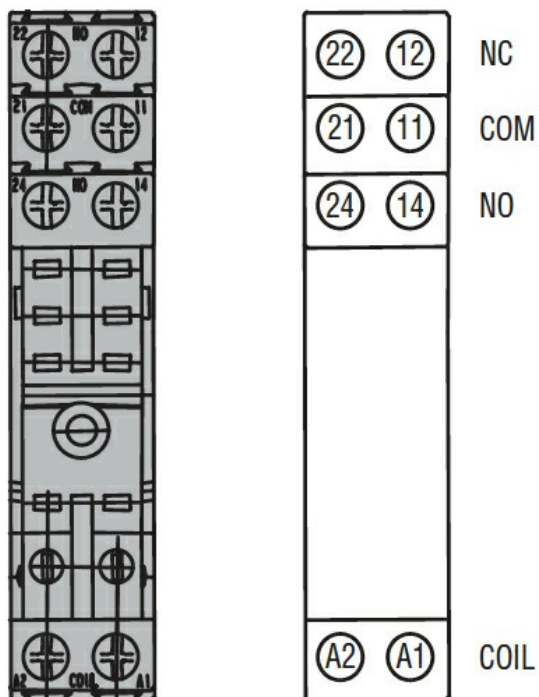

Certifications and compliance

Compliance

IEC/EN 61810

Certificates

CSA

cURus

EAC

ETIM classification

ETIM 8.0

EC001456 -
Relay socket