



Product designation

SOCKET

Product type designation

HR5XS22

Contact characteristics

Rated insulation voltage U_i IEC/EN

V 250

Rated impulse withstand voltage U_{imp}

kV 4

Mechanical features

Socket screw tightening tool (cross / flat blade)

Phillips 1/4.5mm

Conductor section

AWG/Kcmil

min 20

max 14

IEC


min mm^2 0.5

max mm^2 2.5

Fixing


On 35mm DIN
rail and with
screw

Dimensions

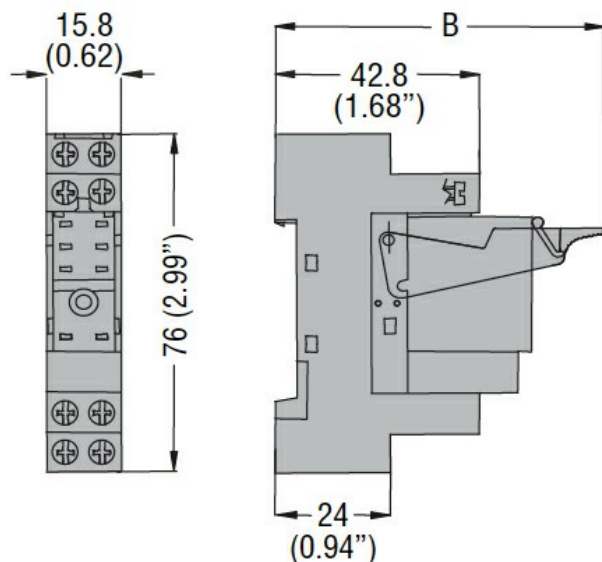

B: 72.5mm (2.85") con HR3X88
82.5mm (3.25) con XR5X88

Wiring diagrams

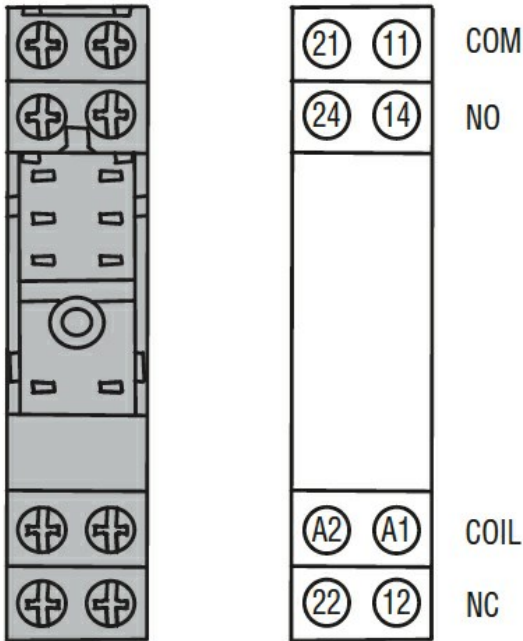

Certifications and compliance

Compliance

IEC/EN 61810

Certificates

- CSA
- cULus
- cURus
- EAC

ETIM classification

ETIM 8.0 EC001456 - Relay socket