



Product designation
Product type designation

SOCKET
HR6XS22

Contact characteristics

Rated insulation voltage U_i IEC/EN	V	250
Rated impulse withstand voltage U_{imp}	kV	4

Mechanical features

Socket screw tightening tool (cross / flat blade)	Phillips 1/4.5mm
---	------------------

Conductor section

AWG/Kcmil

min	20
max	14


IEC

min	mm ²	0.5
max	mm ²	2.5


Fixing

On 35mm DIN
rail and with
screw

Dimensions

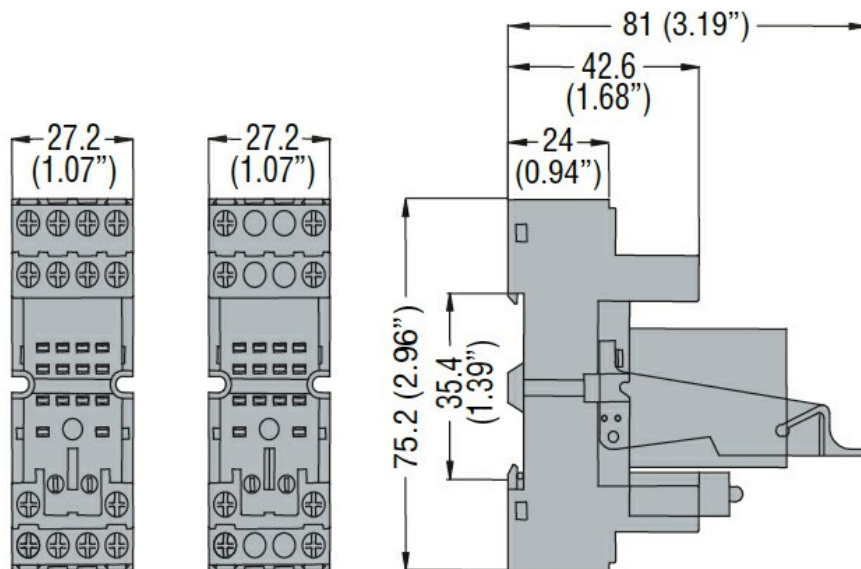

Wiring diagrams

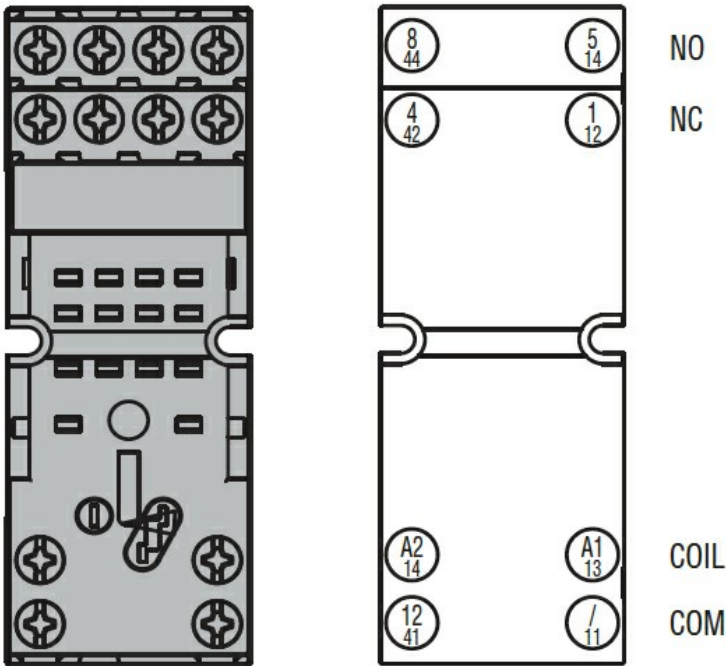

Certifications and compliance

Compliance	IEC/EN 61810
Certificates	CSA
	cURus
	EAC

ETIM classification

ETIM 8.0	EC001456 - Relay socket
----------	-------------------------