





Product designation			SOCKET	
Product type designation			HR5XS21	
Contact characteristics				
Rated insulation voltage Ui IEC/EN			V	250
Rated impulse withstand voltage Uimp			kV	4
Mechanical features				
Socket screw tightening tool (cross / flat blade)			Phillips 1/4.5mm	
Conductor section				
AWG/Kcmil		min		20
		max		14
IEC		min		mm <sup>2</sup> 0.5
		max		mm <sup>2</sup> 2.5
Fixing			DIN rail or with screws	

Dimensions

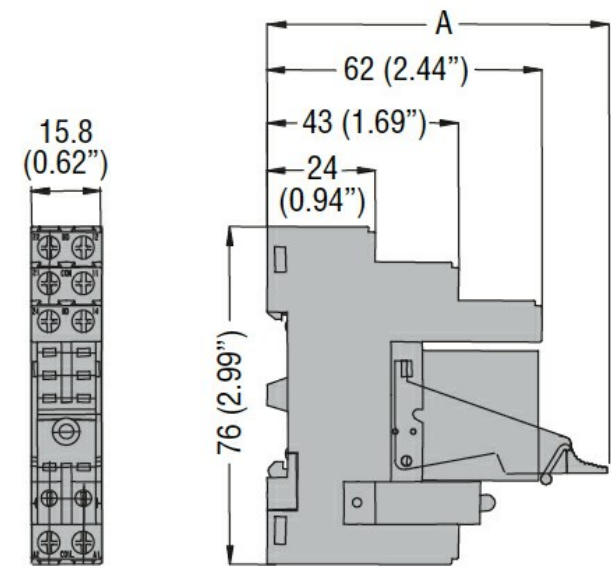

A: 65mm (2.56") con HR3X88  
75mm (2.95") con XR5X88

Wiring diagrams

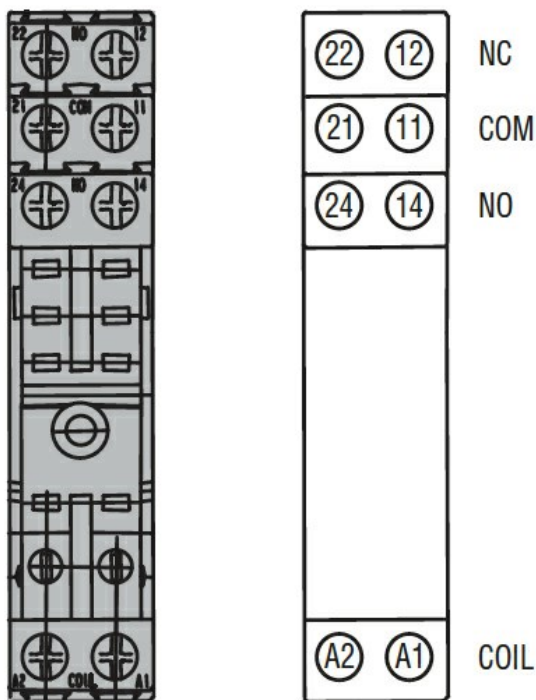

Certifications and compliance

Compliance	IEC/EN 61810
Certificates	CSA
	cURus
	EAC

ETIM classification

ETIM 8.0	EC001456 - Relay socket
----------	----------------------------