



Product designation  
Product type designation

SOCKET  
HR6XS42

#### Contact characteristics

Rated insulation voltage $U_i$ IEC/EN	V	250
Rated impulse withstand voltage $U_{imp}$	kV	4

#### Mechanical features

Socket screw tightening tool (cross / flat blade)	Phillips 1/4.5mm
---	------------------

Conductor section

AWG/Kcmil

min	20
max	14


IEC

min	mm <sup>2</sup>	0.5
max	mm <sup>2</sup>	2.5


Fixing

On 35mm DIN  
rail and with  
screw

#### Dimensions

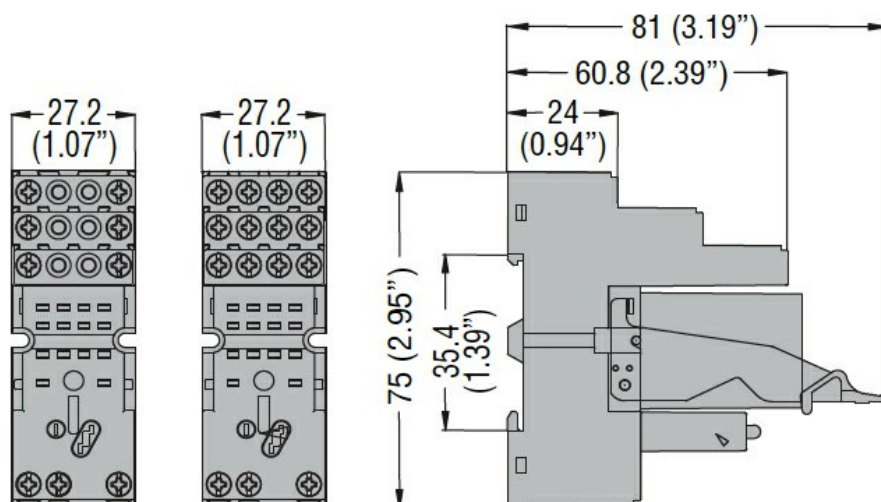

#### Wiring diagrams

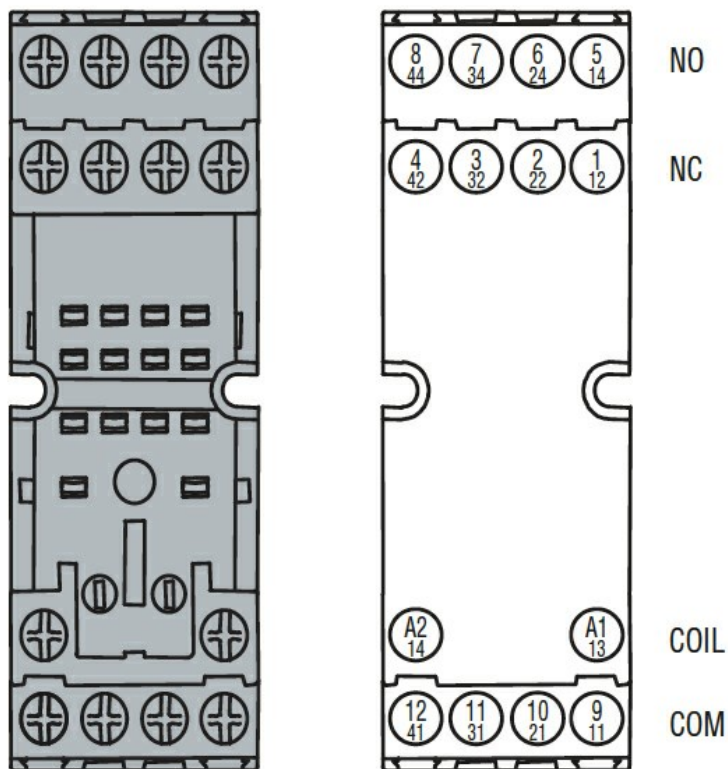

**Certifications and compliance**

Compliance	IEC/EN 61810
Certificates	CSA
	cURus
	EAC

**ETIM classification**

ETIM 8.0	EC001456 - Relay socket
----------	-------------------------