



Mushroom head  
pushbutton,  
Latch, turn to  
release Ø  
40mm/1.6"  
LPCB664

## Product designation

## Product type designation

### General characteristics

Colour	Red
Type of positions	Mushroom head pushbutton
Material	Polyamide
IEC degree of protection	IP66, IP67 and IP69K

### Mechanical features

Operating force	kg-lb	<0.5Kg / 1.1lb
Mechanical life - Latch actuators	cycles	300000
Mounting adapter		LPXAU120
Weight	g	79

### UL technical data

UL degree of protection	Type1, 2, 3R, 4, 4X, 12, 12K
-------------------------	---------------------------------

### Ambient conditions

#### Temperature


##### Operating temperature

min	°C	-25
max	°C	+70

##### Storage temperature

min	°C	-40
max	°C	+85

### Dimensions

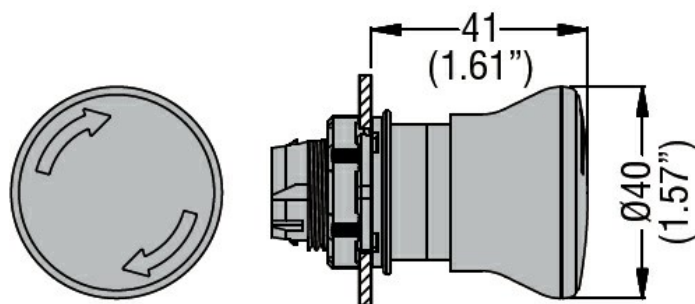

### Certifications and compliance

#### Compliance

CSA C22.2 n° 14  
IEC/EN/BS 60947-1  
IEC/EN/BS 60947-5-1  
UL508

---

Certificates

CCC

cULus

EAC

RINA

UL

ETIM classification

ETIM 8.0

EC001038 -  
Front element for  
mushroom push-  
button