



Product designation
Product type designation

Remote units
RGKRA

Power supply

Rated battery voltage

V 100/240VAC -
12/24VDC

Static Outputs

Static output type

(SSR)

Interface

CANbus

Yes

Mechanical features

Conductor cross section

min	mm ²	0.2
Max	mm ²	2.5
min	AWG	24 or 18 UL/CSA
Max	AWG	12

Tightening torque (Max)


Nm 0.56
lbin 4.5

Ambient conditions


Protection degree

IP54

Dimensions

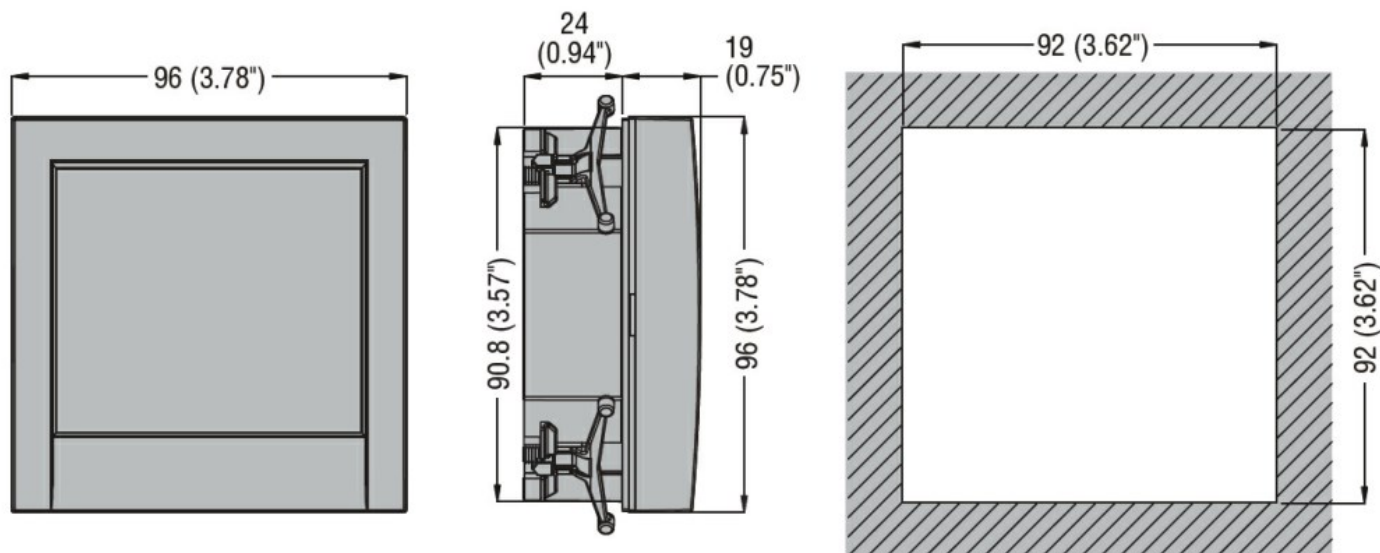

Wiring diagrams

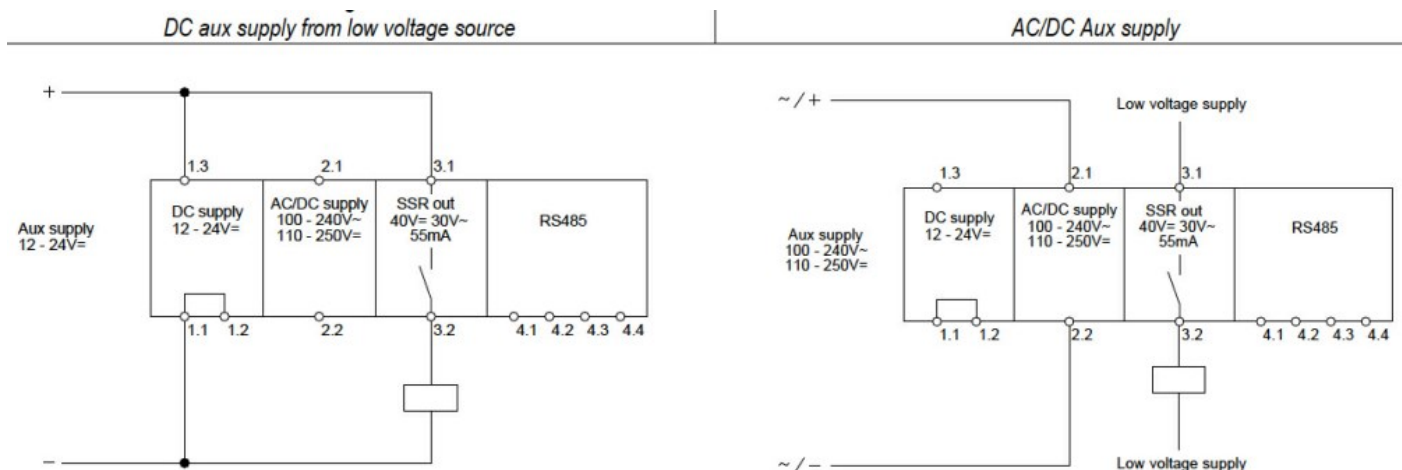

Certifications and compliance

Compliance

CSA C22.2 n° 14

IEC 61000-6-3

IEC/EN 61000-6-2

IEC/EN 61010-1

UL508

Certificates

EAC

UL Listed for USA and Canada (cULus-File E93601)

ETIM classification

ETIM 8.0

EC001427 -
Mobile panel