





Product designation			LED elements	
Product type designation			flashing light	
			8LM2TM	
General characteristics				
Colour			Yellow	
Electrical characteristics				
Rated frequency			Hz	50/60
Supply voltage (AC)			V	18...30
Supply voltage (DC)			V	18...30
Operations				
Electrical life			hours	100000
Mechanical features				
Tightening torque for terminals max			Nm	1
Conductor section				
AWG/kcmil conductor section				
			max	12
IEC				
			max	mm ² 1 or 2 2.5
Mounting adapter			LM2TAU120	
Weight			g	16
Ambient conditions				
Temperature				
Operating temperature				
			min	°C -25
			max	°C +60
Storage temperature				
			min	°C -40
			max	°C +85
Dimensions [mm (in)]				

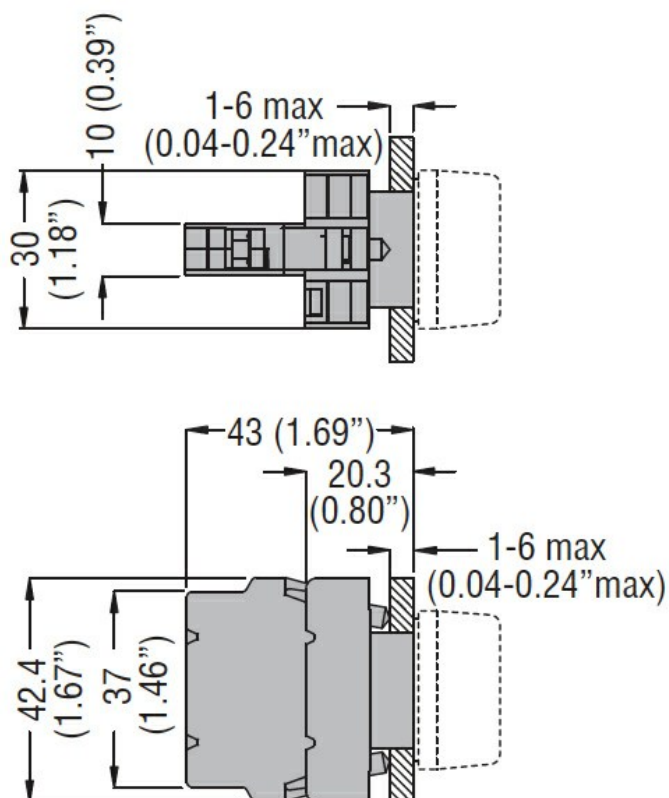

Wiring diagrams

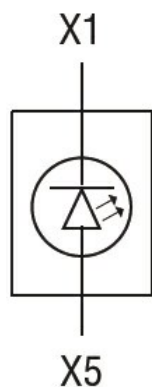

Certifications and compliance

Compliance

CSA C22.2 n° 14
IEC/EN 60947-1
IEC/EN 60947-5-1
UL508

Certificates

CCC
cULus
EAC

ETIM classification

ETIM 8.0

EC000204 -
Lamp holder
block for control
circuit devices