



Product designation

Product type designation

Signal tower  
Ø70mm/2.75"  
8LT7C -  
Connection  
modules

#### General characteristics

Diameter	mm - inch	70 / 2.75
Colour		Black
IEC degree of protection		IP65

#### Mechanical features


Tightening torque for terminals max	Nm	0.5
Terminals screw		Screw clamp terminals

Conductor section	AWG/Kcmil		
		max	16
	IEC		
		max	mm <sup>2</sup> 1.5
Weight		g	120


#### Ambient conditions

Temperature	Operating temperature		
		min	°C -20
		max	°C +50

#### Dimensions

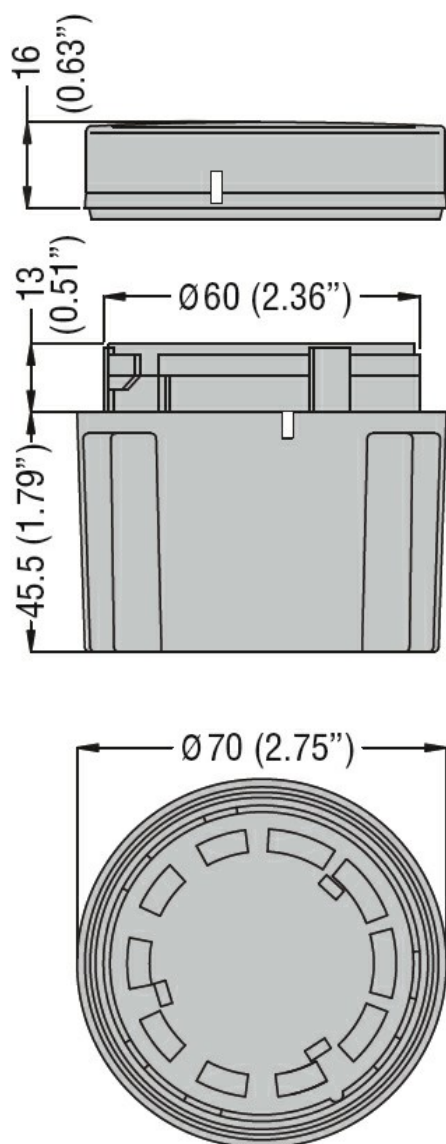

## Wiring diagrams

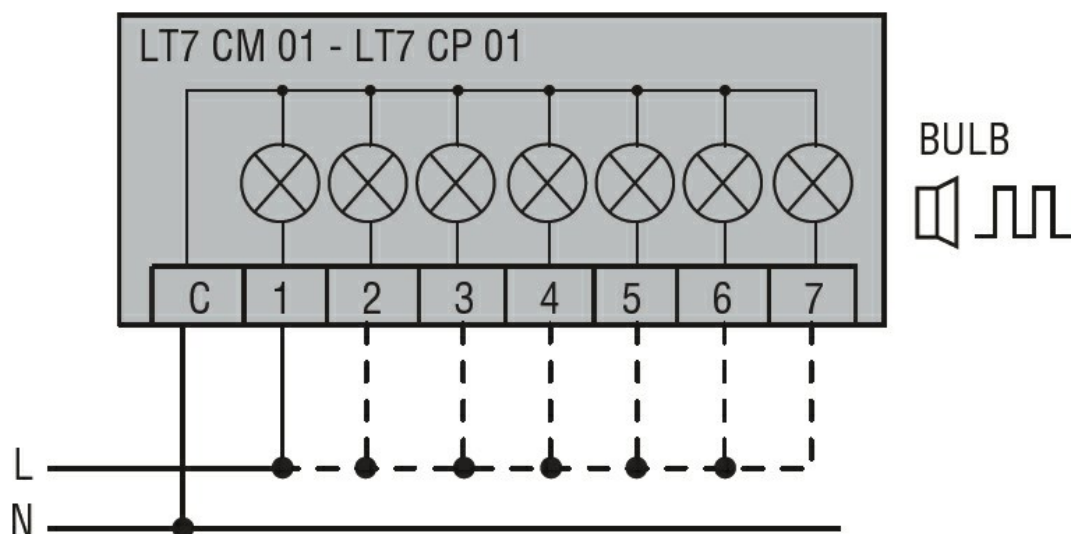

Connect terminals C and 1 as indicated to power the first module.  
If other modules are fitted, the respective terminals must be  
connected accordingly.

#### Certifications and compliance

##### Compliance

CSA C22.2 n°14

IEC/EN 60947-1

IEC/EN 60947-5-1

UL508

##### Certificates

cULus

EAC

#### ETIM classification

ETIM 8.0

EC001152 -  
Connection  
module for signal  
tower