




Product designation	Power distribution block	
Electrical features		
Number of poles		1
Rated insulation voltage Ui	V	1000
IEC Conventional free air thermal current Ith	A	85
Rated peak withstand current Ipk	kA	22
Rated short time current Icw 60s	A	3
Connections		
Terminal hole diameter_Option 1	mm	1x6mm
Conductor section connectable_Option 1	mm2	6...16
	AWG	16...4
Terminal hole diameter_Option 2	mm	4x4.4mm
Conductor section connectable_Option 2	mm2	2.5...6
	AWG	16...8
Terminal hole diameter_Option 3	mm	2x6mm
Conductor section connectable_Option 3	mm2	2.5...16
	AWG	16...4
Mechanical features		
Operating position	normal allowable	Vertical plane Any
Fixing		Screw / DIN rail 35mm
Metric Allen Key	mm	2,5-3
Weight	g	72
Resistance & Protection		
Terminals IP degree		IP20 front
Dimensions		

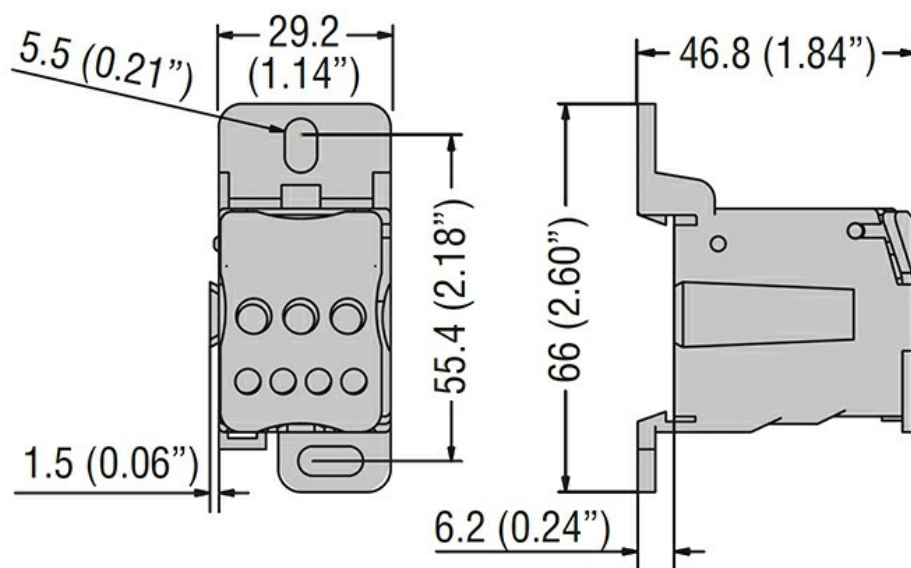

Certifications and compliance

Certifications

IEC/EN/BS 60947-7-1

Compliance

cURus

ETIM classification

EC000066 - Power contactor, AC switching

□