




Product designation	Power distribution block	
Electrical features		
Number of poles		1
Rated insulation voltage Ui	V	1000
IEC Conventional free air thermal current Ith	A	255
Rated peak withstand current Ipk	kA	51
Rated short time current Icw 60s	A	24.5
Connections		
Terminal hole diameter_Option 1	mm	1x16mm
Conductor section connectable_Option 1	mm2	35...120
Terminal hole diameter_Option 2	mm	2x9,5mm
Conductor section connectable_Option 2	mm2	6...25
Terminal hole diameter_Option 3	mm	5x7mm
Conductor section connectable_Option 3	mm2	2,5...16
Mechanical features		
Operating position	normal allowable	Vertical plane Any
Fixing		Screw / DIN rail 35mm
Metric Allen Key	mm	3-4-5-8
Weight	g	405
Resistance & Protection		
Terminals IP degree		IP20 front
Dimensions		

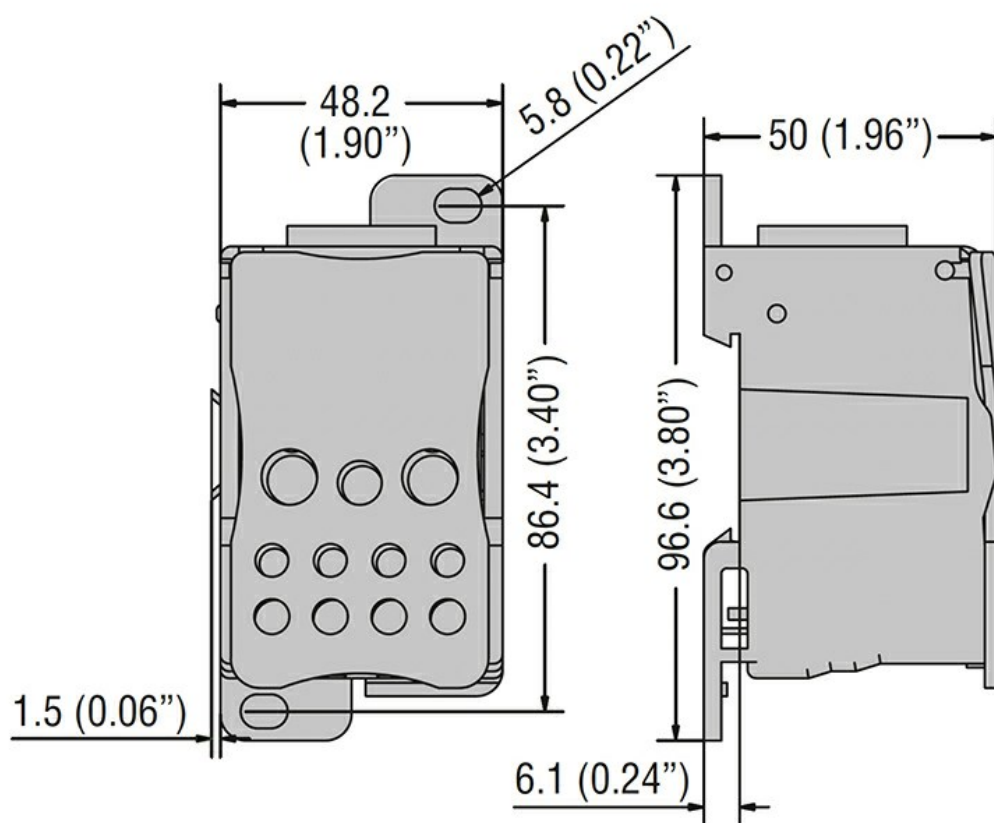

#### Certifications and compliance

##### Certifications

IEC/EN/BS 60947-7-1

##### Compliance

cURus

#### ETIM classification

EC000066 - Power contactor, AC switching